

exacqVision LC-Series IP & Hybrid Appliance



• All-in-One IP Solutions

- Record IP cameras, encoders and analog cameras
- Available in hybrid and IP NVR models
- View live and recorded video through free exacqVision client application

• Connect up to 32 Cameras Per Appliance

- Connect up to 16 analog cameras and 16 IP cameras per appliance
- Compatible with thousands of IP camera models
- Continuously record up to 100 Mbps of video

• Powerful, Easy-to-Use VMS Included

- Pre-loaded with exacqVision Start VMS software that does the following:
 - Auto detects IP cameras for quick setup
 - Easily add additional IP cameras, up to 16 total
 - Continuous motion, time or alarm-based recording configurable per camera
 - Search recorded video with a timeline or graphical thumbnail search
 - Easily control PTZ cameras
 - Export audio, video and pictures to be easily e-mailed or saved
 - View an instant replay of video from any camera with exacqReplay

• Optional Input/Output Module

- Add configurable trigger inputs and outputs with an optional external USB I/O module

• View Video Anywhere with Free Client Software

- Select the interface that works best for you
- Access live and recorded video on Windows, Linux or Mac PCs
- Use the free web service application in any modern browser
- Download the free Exacq Mobile app available for iOS, Android, Windows Phone 8 and Kindle Fire

• 3-Year Warranty

- Includes a 3-year hardware warranty
- 3 years of unlimited software updates included


• Easily Upgrade to exacqVision Pro VMS Software

- Use appropriate part number to automatically upgrade analog licenses and 4 included IP licenses
- Simply add IP addresses as needed

exacqVision **LC-Series**

ANALOG SETTINGS	IPS	HYBRID
Inputs		8/16
Compression		H.264
Frame Rate		240/480 (NTSC) 200/400 (PAL)
Alarm Inputs	Up to 48 (Optional External)	Up to 48 (Optional External)
Alarm Outputs	Up to 20 24 TTL, 6 Relay (Optional External)	Up to 20 24 TTL, 6 Relay (Optional External)
Analog Outputs		1 multiplexed
Audio Inputs		8/16
IP SETTINGS	IPS	HYBRID
Maximum IP Cameras	16	16
Included IP Licenses	4	4
SERVER	IPS	HYBRID
Pre-Loaded VMS Software	Start (standard), Professional, Enterprise (optional)	Start (standard), Professional, Enterprise (optional)
Typical Video Storage Rate (Mbps)	100 Mbps	100 Mbps
Local Client Display Rate (FPS)	150 @ HD resolution 600 @ analog resolution	150 @ HD resolution 600 @ analog resolution
Maximum Hard Drives	1	1
Maximum Storage	12T B	12 TB
Monitor Output	HDMI, VGA	HDMI, VGA
Operating System	Ubuntu Linux 14.04	Ubuntu Linux 14.04
CPU	Intel Celeron	Intel Celeron
RAM	4 GB	4 GB
NIC	2 x 1 Gbps	1 x 1 Gbps
USB	6 (2 front, 4 rear)	6 (2 front, 4 rear)
Keyboard & Mouse	Included	Included
GENERAL	IPS	HYBRID
Dimensions	10.9" x 16.9" x 3.5" 27.7 x 42.9 x 8.9 cm	10.9" x 16.9" x 3.5" 27.7 x 42.9 x 8.9 cm
Weight	14 lbs. 6.4 kg	14 lbs. 6.4 kg
Regulatory	CE, FCC, cULus, UL Listed	CE, FCC, cULus, UL Listed
Power & Heat	40 Watts/135 BTU/h (Typical) 60 Watts/200 BTU/h (Max)	45 Watts/150 BTU/h (Typical) 70 Watts/240 BTU/h (Max)
Operating Temperature	40° - 95° F 4.5° - 35° C	40° - 95° F 4.5° - 35° C

Related Products

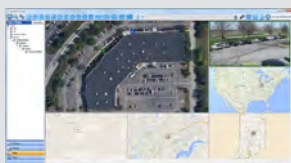

exacqVision VMS Software



Exacq Mobile App



exacqVision
E-Series Encoders



exacqVision A-Series
hybrid NVR



exacqVision Surveillance
Keyboard

www.exacq.com