



555856-2
AMPINNERGY® Power Entry Cable Assembly, 8-wire/4-circuit (4-2-2), shared neutral, 3 feet

- Used to interface between manufactured wiring and other wiring systems, such as building wiring, fixture wiring, or access floor module wiring
- Mates to line connector cable assemblies, power junction boxes, power distribution modules (PDMs), zone distribution modules (ZDBs) and power transition units (PTUs)

Product Classification

Brand	AMPINNERGY®
Product Series	AMPINNERGY
Product Type	Power entry cable assembly
Regional Availability	North America

Configuration Features

Neutral Type	10/12 AWG Shared
Wiring Pattern	8-Wire/4 Circuit (4-2-2)

Dimensions

Cable Length	0.91 m 3.00 ft
Length of exposed conductors	304.80 mm 12.00 in

Electrical Characteristics


Current Rating	20 A
Voltage Rating	125 Vac 250 Vac

Industry Standards

Standards Compliance	CEC 2015 § 12-010 CEC 2015 § 12-2500 CSA 22.2 number 203 CSA 22.2 number 203.1 CSA 22.2 number 42 CSA Certified, File: 7189 NEC 2013 § 300.22 (c) NEC 2013 § 604 NEC 2013 § 605 UL 1286, File: E101904 UL 183, File: E132626 UL 498, File: E146448
----------------------	--

Outline Drawing

555856-2

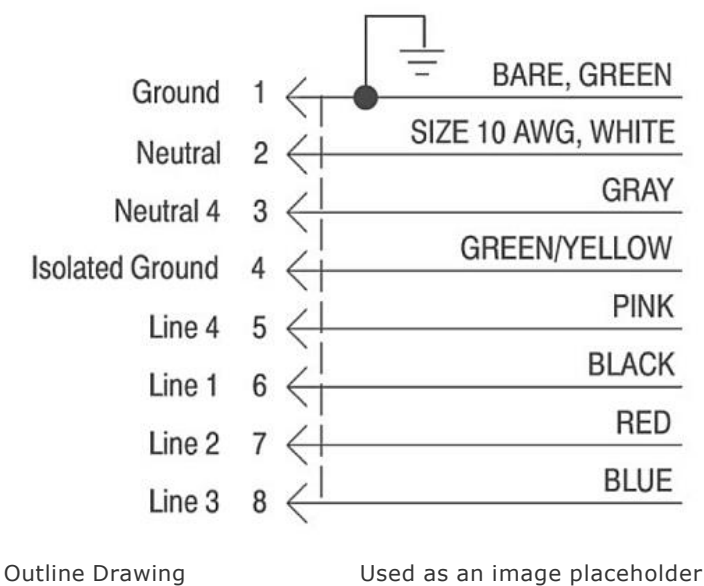

Outline Drawing

Used as an image placeholder

Packaging Features

Packaging Method	Bag
Packaging Quantity	1

Product Type Features

Cable Assembly Type	Line entry
Cable Style	Corrugated hose
Connector Type (End A)	Power male plug
Connector Type (End B)	Stub Tail

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU

Classification

Compliant