



692543-000 | FOSC400-B2-24-1-NGV

FOSC™400 B2 Fiber Optic Splice Closure, Heat Shrink Cable sealing, one pre-installed 24-splice tray, ground feedthrough lugs, with test valve

- Single-ended, O-ring sealed dome closure for splicing feeder and distribution cables
- Compatible with most common cable types: e.g. loose tube, central core, ribbon fiber
- FOSC splice trays hinged for access to any splice without disturbing other trays
- Closure can be used in aerial, pedestal and underground (up to 5 meters) environments
- Compatible with CommScope's CWDM modules and optical splitter trays

Product Classification

Brand	FOSC™
Product Series	FOSC 400
Product Type	Butt feeder and distribution closure
Regional Availability	Latin America North America

Body Features

Cable Seal	Heat Shrink
Color	Black

Configuration Features

Port Shape	Oval (1) and round (2)
Flash Test Valve	Yes
Number of Pre-installed Splice Trays	24-fiber (1)
Ground Feedthrough	Yes
Slack Basket	Optional


Dimensions

Closure Diameter	150.000 mm 5.906 in
Length	540.00 mm 21.26 in

Operation/Application

Environment	Direct burial Manholes
-------------	--------------------------

Outline Drawing

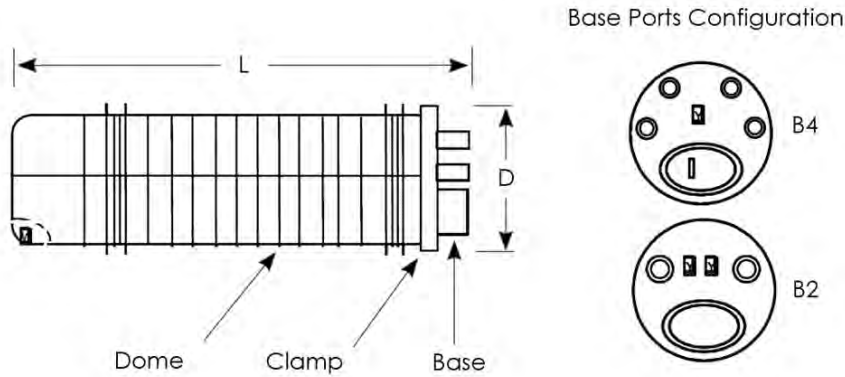

Packaging Features

Minimum Order Quantity	1
Packaging Method	Box/Carton

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant