

Stainless-Steel QuickPort® Wallplates with ID Windows

APPLICATION

Leviton single-gang and dual-gang Stainless-Steel Wallplates with ID Windows offer flexibility and accept QuickPort snap-in connectors and adapters to support a variety of commercial and residential applications. Available in several port configurations; the single-gang wallplate comes in 1, 2, 3, 4, or 6 ports, and the dual-gang version comes in 2, 4, 6, 8, or 12 ports.



SPECIFICATION

Single-gang and dual-gang stainless-steel wallplates shall be field configurable, and accept QuickPort snap-in connectors and adapters to support commercial and residential applications. The single-gang wallplate shall provide 1, 2, 3, 4, or 6 ports, and the dual-gang wallplate shall provide 2, 4, 6, 8, or 12 ports. Each wallplate shall have a brushed stainless-steel finish, fit standard NEMA electrical boxes, be cULus Listed, and compliant with ANSI/TIA-568-C.0 specifications.

FEATURES

- Compatible with all individual QuickPort connectors and adapters
- Fits standard NEMA electrical boxes
- Includes ID windows for each wallplate
- Individual port configurability allows specification flexibility
- Brushed stainless-steel finish

DESIGN CONSIDERATIONS

- Fits standard NEMA single- and dual-gang back boxes
- Not recommended for use with metal or plastic remodeler's-type mud rings
- For future expansion, install blanks (41084-BxB) in unused ports
- Specify port identification method (colored modules, designation labels, and custom silk-screening available)
- To identify ports, use different colored connectors for each application, or Leviton pre-printed Port Designation Labels (41080-LEB)

STANDARDS COMPLIANCE

- ANSI/TIA-568-C.0
- cULus Listed (UL 1863 & CAN/CSA-C22.2 No. 182.4)

PHYSICAL SPECIFICATIONS

Dimensions:	See page two
Materials:	Type 304 stainless steel, ABS plastic carrier
Capacity:	Single-gang: 1-, 2-, 3-, 4- or 6-port versions Dual-gang: 2-, 4-, 6-, 8- or 12-port versions

COUNTRY OF ORIGIN

Taiwan

WARRANTY INFORMATION

For a copy of Leviton product warranties, visit www.leviton.com/warranty.

43080-1Lx 43080-2Lx, 43080-L12


PRODUCT SPECIFICATIONS

43080-1Lx 43080-2Lx, 43080-L12



ELECTRONIC FILES

For CAD files, typical specs, or technical drawings (.DXF, .DWG), visit www.leviton.com.

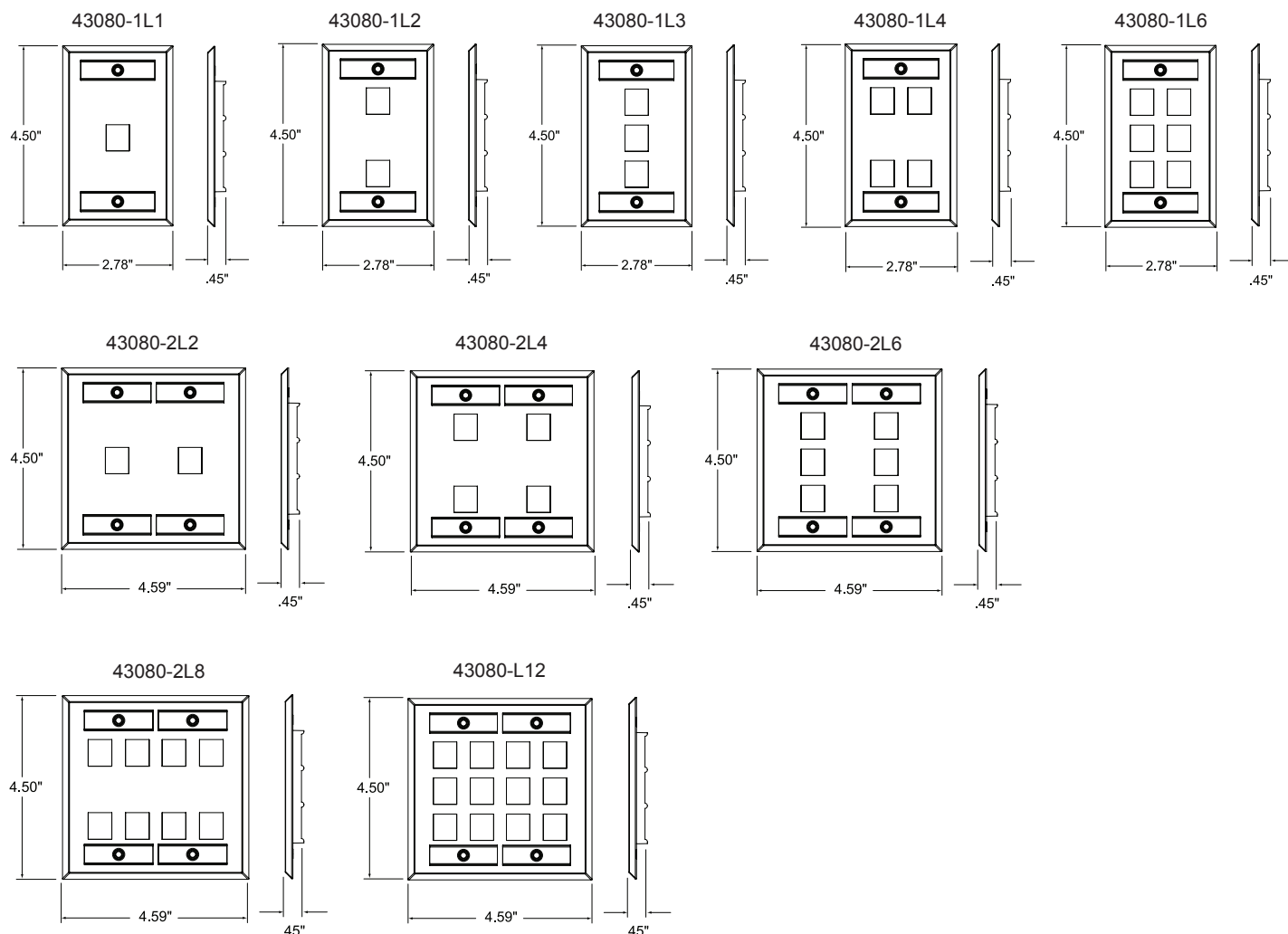

43080-1Lx 43080-2Lx, 43080-L12

PART NUMBERS

Description

Part No.

Stainless-Steel QuickPort® Wallplate with ID Window, Single Gang

43080-1Lx

Stainless-Steel QuickPort Wallplate with ID Window, Dual Gang

43080-2Lx

Stainless-Steel QuickPort Wallplate with ID Window, Dual Gang, 12 Ports

43080-L12

x = Single-Gang available in One (1), Two (2), Three (3), Four (4), or Six (6) Ports
x = Dual-Gang available in Two (2), Four (4), Six (6), or Eight (8) Ports



Leviton Network Solutions
2222 - 222nd St. SE
Bothell, WA 98021-4416

Asia / Pacific
T +1.631.812.6228
E infoasean@leviton.com

Canada
T +1.514.954.1840
E pcservice@leviton.com

Caribbean
T +1.954.593.1896
E infocaribbean@leviton.com

China
T +852.2774.9876
E infochina@leviton.com

Colombia
T +57.1.743.6045
E infocolombia@leviton.com

tel 1-800-824-3005
tel +1-425-486-2222
appeng@leviton.com
www.leviton.com

Europe
T +33.6.8869.1380
E infoeurope@leviton.com

India / SAARC
T +971.4.886.4722
E infoindia@leviton.com

Mexico
T +52.55.5082.1040
E Isamarketing@leviton.com

Middle East & Africa
T +971.4.886.4722
E lmeinfo@leviton.com

South Korea
T +82.2.3273.9963
E infokorea@leviton.com