


## QuickPort® Fiber Optic Adapters ST, FC, SC, LC, MT-RJ, and MTP

### APPLICATION

QuickPort Fiber Optic Adapters provide connectivity for workstation cabling termination on single mode and multimode fiber cable. QuickPort bulkhead modules snap into any housing with the QuickPort name: flush and surface mount outlets; Multimedia Outlet System (with adapter); patch panels, and patch blocks.

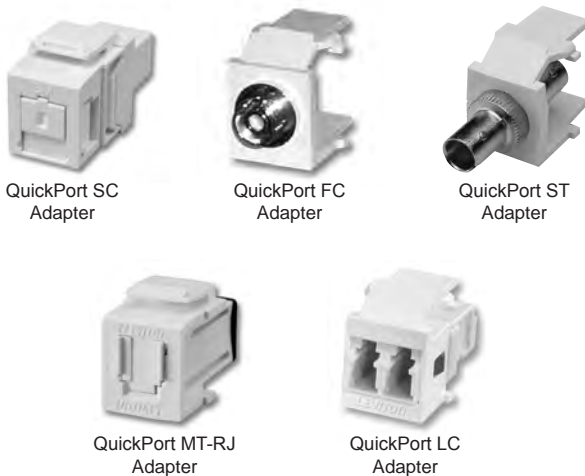

### SPECIFICATION

QuickPort Fiber Optic Adapters for fiber optic cabling media shall be individual snap-in style and shall fit into QuickPort housings. The ST, FC, SC, and LC Adapters shall be compatible with single-mode, multimode, and laser optimized multimode connectors, and available in zirconia ceramic or phosphor bronze sleeves. ST, FC, MT-RJ, MTP, and SC QuickPort Adapters shall be available in standard colors of ivory, white, grey, black and almond. SC QuickPort Adapters shall also be available in blue for identification in single-mode applications. LC QuickPort adapters shall be available in standard colors as well as blue, yellow, red, green, and orange as part of the Secure Keyed LC system.

### DESIGN CONSIDERATIONS

- Quickport adapters snap into QuickPort panels or modules.
- ST, FC, and SC QuickPort Adapters are available in standard colors of ivory, white, grey, black, and almond
- SC QuickPort Adapters are also available in blue for identification in single-mode applications
- LC QuickPort adapters are available in standard colors as well as blue, yellow, red, green, and orange as part of the Secure Keyed LC system
- Use in permanent or temporary applications
- ST, FC, SC, and LC QuickPort Adapters are available in zirconia ceramic or phosphor bronze sleeves, and are compatible with single-mode or laser optimized multimode applications

### STANDARDS COMPLIANCE

UL Listed; NOM and ACA certified; compliant with TIA-568-C.3  
 TIA 604

### PHYSICAL SPECIFICATIONS

Dimensions:

ST Fiber Adapter:	.644" H x .575" W x 1.3" D
FC Fiber Adapter:	.644" H x .575" W x 1.01" D
SC Fiber Adapter:	.644" H x .575" W x 1.354" D
LC Fiber Adapter:	.644" H x .575" W x 1.414" D
MT-RJ Fiber Adapter:	.644" H x .575" W x 1.102" D


Materials:	Snap in module bodies are high-impact, fire retardant plastic rated UL 94V-0
ST Fiber Adapter:	Single-mode zirconia sleeve LOMM zirconia sleeve Multimode phosphor bronze sleeve
FC Fiber Adapter:	Single-mode zirconia sleeve LOMM zirconia sleeve Multimode phosphor bronze sleeve
SC Fiber Adapter:	Single-mode zirconia sleeve LOMM zirconia sleeve Multimode phosphor bronze sleeve
LC Fiber Adapter:	Single-mode zirconia sleeve LOMM zirconia sleeve Multimode phosphor bronze sleeve
MT-RJ Fiber:	MT-RJ coupling
MTP:	MTP coupling

### WARRANTY INFORMATION

For a copy of Leviton product warranties, visit [www.leviton.com](http://www.leviton.com).

**ELECTRONIC FILES**


For CAD files, typical specs, or dimensional line art. (.DXF, .DWG, Visio), visit [www.leviton.com](http://www.leviton.com).

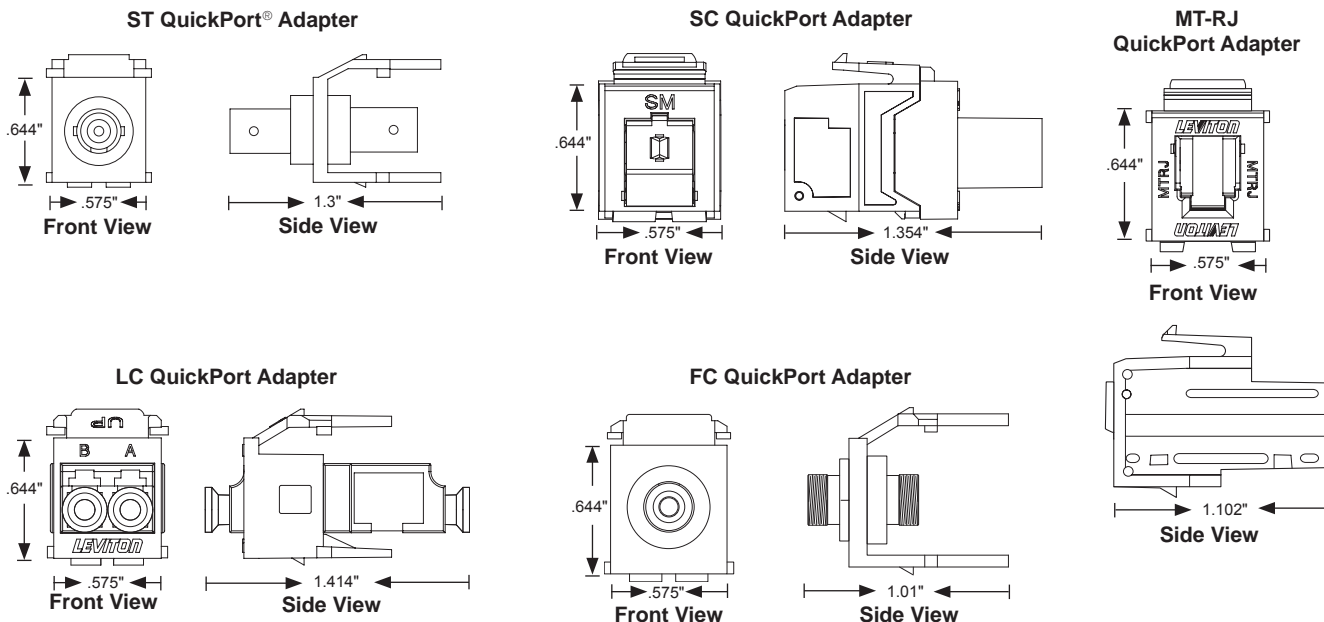

41084-XXX, 41085-XXX, 49889-QFX

QuickPort Fiber Optic Adapters	
Description	Part No.
MT-RJ QuickPort Adapter, MM, no almond	49889-QF*
ST QuickPort Fiber Optic Adapter, MM, Phosphor Bronze Sleeve	41084-S*F
ST QuickPort Fiber Optic Adapter, SM/LOMM, Zirconia Ceramic Sleeve	41084-S*Z
FC QuickPort Fiber Optic Adapter, MM, Phosphor Bronze Sleeve	41084-F*P
FC QuickPort Fiber Optic Adapter, SM/LOMM Zirconia Ceramic Sleeve	41084-F*Z
SC QuickPort Fiber Optic Adapter, MM, Phosphor Bronze Sleeve	41085-M*C
SC QuickPort Fiber Optic Adapter, SM/LOMM Zirconia Ceramic Sleeve	41085-S*C
Duplex LC QuickPort Fiber Optic Adapter, Beige, MM, Phosphor Bronze Sleeve	41085-ML+
Duplex LC QuickPort Fiber Optic Adapter, Aqua, Zirconia Ceramic Sleeve	41085-LL+
Duplex LC QuickPort Fiber Optic Adapter, Blue, SM, Zirconia Ceramic Sleeve	41085-SL+
MTP QuickPort Adapter, SM/MM	41085-TP*

 - \* = Colors: Ivory (I), White (W), Grey (G), Black (E), Almond (A)
- = Colors: Ivory (I), White (W), Grey (G), Black (E), Almond (A), Blue (B)
- + = Colors: Ivory (I), White (W), Grey (G), Black (E), Almond (A), Yellow (Y), Red (R), Blue (B), Green (V), Orange (O)



**Leviton Network Solutions**  
2222 - 222nd St. SE  
Bothell, WA 98021-4416

**Asia / Pacific**  
T +1.631.812.6228  
E [infoasean@leviton.com](mailto:infoasean@leviton.com)

**Canada**  
T +1.514.954.1840  
E [pcservice@leviton.com](mailto:pcservice@leviton.com)

**Caribbean**  
T +1.954.593.1896  
E [infocaribbean@leviton.com](mailto:infocaribbean@leviton.com)

**China**  
T +852.2774.9876  
E [infochina@leviton.com](mailto:infochina@leviton.com)

**Colombia**  
T +57.1.743.6045  
E [infocolombia@leviton.com](mailto:infocolombia@leviton.com)

tel 1-800-824-3005  
tel +1-425-486-2222  
[appeng@leviton.com](mailto:appeng@leviton.com)  
[www.leviton.com](http://www.leviton.com)

**Europe**  
T +33.6.8869.1380  
E [infoeurope@leviton.com](mailto:infoeurope@leviton.com)

**India / SAARC**  
T +91.80.4322.5678  
E [infoindia@leviton.com](mailto:infoindia@leviton.com)

**Mexico**  
T +52.55.5082.1040  
E [Esamarketing@leviton.com](mailto:Esamarketing@leviton.com)

**Middle East & Africa**  
T +971.4.886.4722  
E [lmeinfo@leviton.com](mailto:lmeinfo@leviton.com)

**South Korea**  
T +82.2.3273.9963  
E [infokorea@leviton.com](mailto:infokorea@leviton.com)