


Technical drawing of a bolt and nut assembly. The drawing shows a bolt with a hexagonal head and a nut. Dimension A is the width of the bolt head, and dimension B is the height of the bolt head. The bolt is shown in a cross-section view, and the nut is shown in a side view.

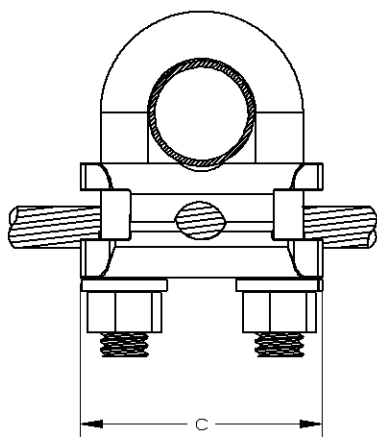

 C US
 467
 LISTED
 SUITABLE FOR
 DIRECT BURIAL

PANDUIT PART NUMBER	ACCOMODATES		CONDUCTOR RANGE	DIMENSIONS - IN [mm]						BOLT DIA
	ROD DIA	NOMINAL PIPE SIZE (IPS)		A		B		C		
				IN	MM	IN	MM	IN	MM	
GPL-4-Q	5/8" OR 3/4"	3/8"	#8 SOL - #4 STR	1.38	34	2.75	70	2.00	51	0.38
GPL-5-Q	5/8" OR 3/4"	3/8"	#4 SOL - 2/0 STR	1.63	41	2.75	70	2.00	51	0.38
GPL-6-Q	5/8" OR 3/4"	3/8"	2/0 SOL - 250 kcmil	1.88	47	2.75	70	2.00	51	0.38
GPL-8-Q	7/8" OR 1"	1/2" OR 3/4"	#8 SOL - #4 STR	1.38	34	2.63	67	2.38	60	0.38
GPL-9-Q	7/8" OR 1"	1/2" OR 3/4"	#4 SOL - 2/0 STR	1.63	41	2.63	67	2.38	60	0.38
GPL-10-Q	7/8" OR 1"	1/2" OR 3/4"	2/0 SOL - 250 kcmil	1.88	47	3.00	76	2.38	60	0.38
GPL-14-X	----	1"	#8 SOL - #4 STR	1.38	34	2.75	70	2.63	67	0.38
GPL-15-X	----	1"	#4 SOL - 2/0 STR	1.63	41	2.75	70	2.63	67	0.38
GPL-16-X	----	1"	2/0 SOL - 250 kcmil	1.88	47	3.25	82	2.63	67	0.38
GPL-20-X	----	1-1/4"	#8 SOL - #4 STR	1.38	34	3.50	89	3.00	76	0.38
GPL-21-X	----	1-1/4"	#4 SOL - 2/0 STR	1.63	41	3.50	89	3.00	76	0.38
GPL-22-X	----	1-1/4"	2/0 SOL - 250 kcmil	1.88	47	3.50	89	3.00	76	0.38
GPL-26-X	----	1-1/2"	#8 SOL - #4 STR	1.38	34	4.00	102	3.25	82	0.38
GPL-27-X	----	1-1/2"	#4 SOL - 2/0 STR	1.63	41	4.00	102	3.25	82	0.38
GPL-28-X	----	1-1/2"	2/0 SOL - 250 kcmil	1.88	47	4.00	102	3.25	82	0.38
GPL-32-3	----	2"	#8 SOL - #4 STR	1.38	34	4.25	108	3.75	95	0.38
GPL-33-3	----	2"	#4 SOL - 2/0 STR	1.63	41	4.25	108	3.75	95	0.38
GPL-34-3	----	2"	2/0 SOL - 250 kcmil	1.88	47	4.25	108	3.75	95	0.38
GPL-39-3	----	2-1/2"	#4 SOL - 2/0 STR	1.63	41	5.00	127	4.25	108	0.38
GPL-40-3	----	2-1/2"	2/0 SOL - 250 kcmil	1.88	47	5.00	127	4.25	108	0.38
GPL-44-1	----	3"	#8 SOL - #4 STR	1.38	34	5.50	140	4.75	121	0.38
GPL-45-1	----	3"	#4 SOL - 2/0 STR	1.63	41	5.50	140	4.75	121	0.38
GPL-46-1	----	3"	2/0 SOL - 250 kcmil	1.88	47	5.50	140	4.75	121	0.38
GPL-51-1	----	3-1/2"	#4 SOL - 2/0 STR	1.63	41	6.25	158	5.25	133	0.38
GPL-52-1	----	3-1/2"	2/0 SOL - 250 kcmil	1.88	47	6.25	158	5.25	133	0.38
GPL-57-1	----	4"	#4 SOL - 2/0 STR	1.63	41	6.38	161	5.75	146	0.38
GPL-58-1	----	4"	2/0 SOL - 250 kcmil	1.88	47	6.38	161	5.75	146	0.38

[illegible]