



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	1/0 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1.0 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90 ° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	PINK
Panduit Die Index No. on Barrel	P42
Alternate Industry Die Index No. () on Barrel	(12)

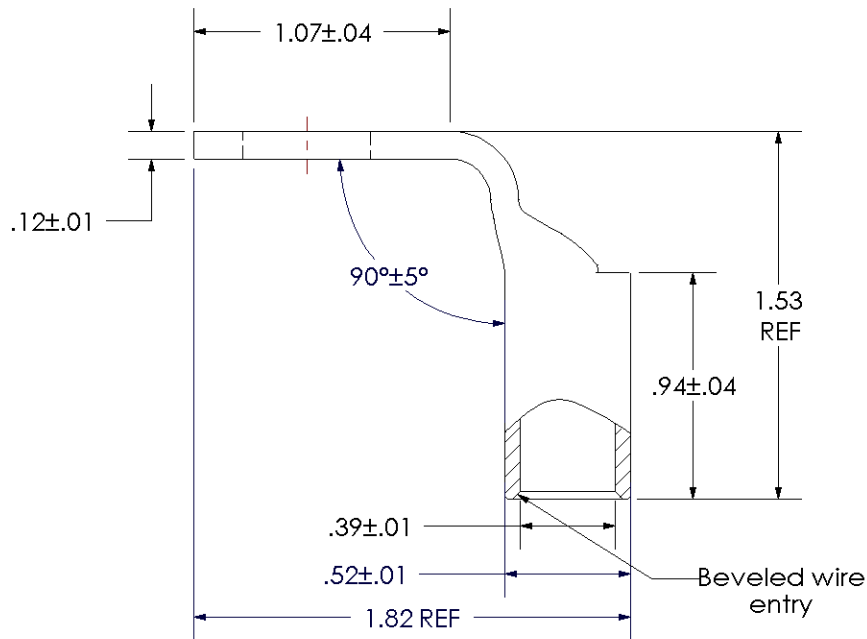

LISTED
Wire Connector

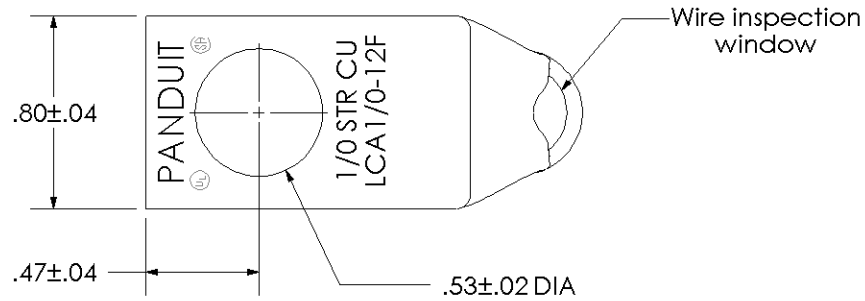

01	3/04	DRL	DRL	ADDED UL, CSA AND PART NO. TO STAMP	11656
REV	DATE	BY	CHK	DESCRIPTION	ECN

PANDUIT

CORP. TINLEY PARK, ILLINOIS

LCA1/0-12F-X
Copper Lug - One-Hole, Standard Barrel, 90° Angle Tongue

SCALE
N/A

DRAWING NO / CAD FILE

LCA1_0-12F-CUST