

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	4/0 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/4 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90 ° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	PURPLE
Panduit Die Index No. on Barrel	P54
Alternate Industry Die Index No. () on Barrel	(15)




CERTIFIED



LISTED

Wire Connector

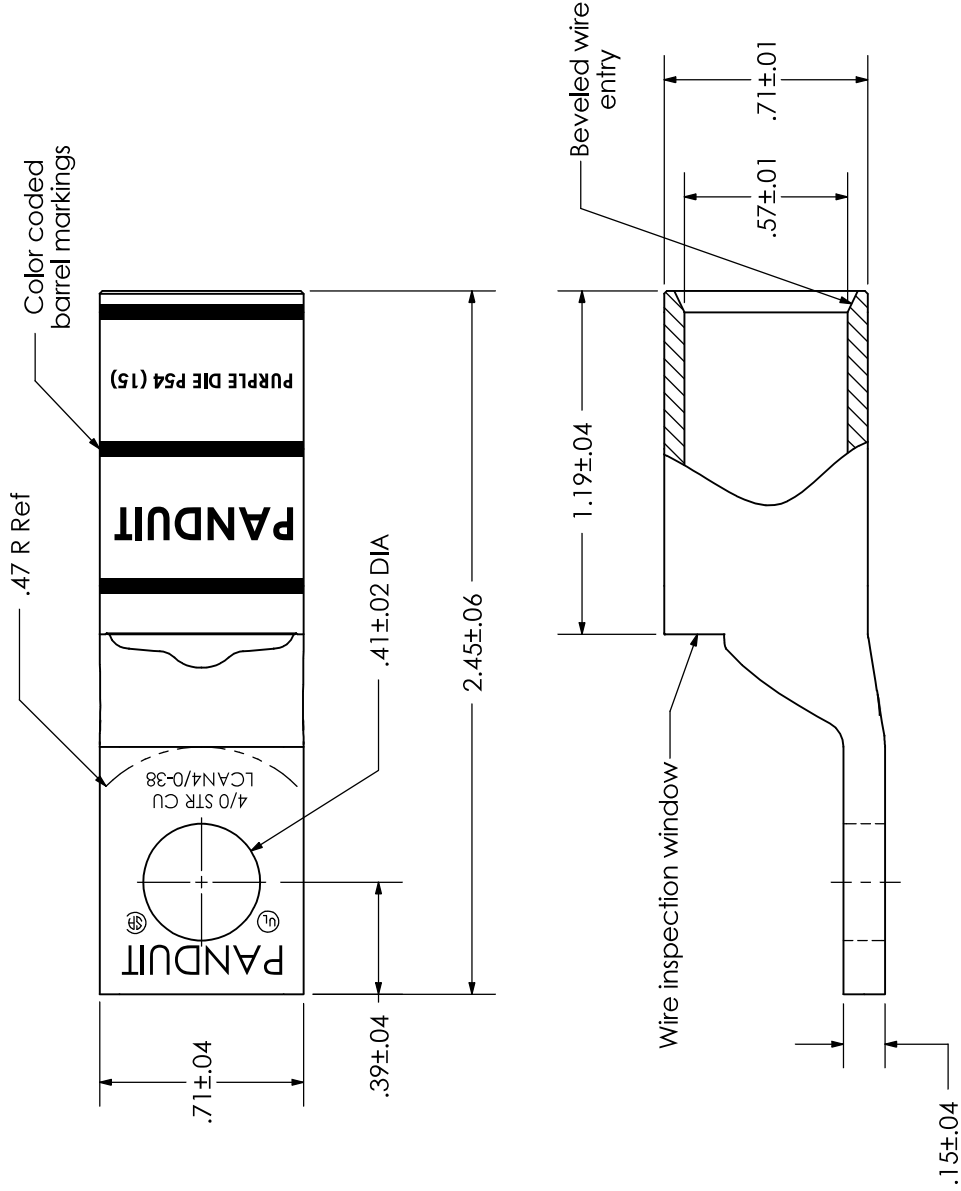

								PANDUIT CORP. TINLEY PARK, ILLINOIS	
								LCAN4/0-38-X	
								Copper Lug - One-Hole, Narrow Tongue, Standard Barrel	
								SCALE	N/A
								DRAWING NO / CAD FILE	LCAN4_0-38-CUST
								ECN	
								DESCRIPTION	
								TONGUE THICKNESS WAS .14±.01	
01	11/08	DRL	DRL						
REV	DATE	BY	CHK						