


Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	2 STR/FLEX
Wire Type	Stranded Copper: Class B & C, Compact, Class G, H, I, K, M, Locomotive
Wire Strip Length	11/16 in.
Stud Size	3/8 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BROWN
Panduit Die Index No. on Barrel	P33
Alternate Industry Die Index No. () on Barrel	(10)



Technical drawing of a Panduit LCAX2-38F connector. The drawing shows a side view of the connector with dimensions and labels. The main body is rectangular with a circular port on the left. The port is labeled "2 STR/FLEX LCAX2-38F". The main body is labeled "PANDUIT". The connector has a tapered end on the right, labeled "Wire inspection window". Dimensions are given as follows: .70±.04 for the total height, .36±.04 for the height of the main body, and .41±.02 DIA for the diameter of the port. There are also labels for "ST" and "LC" near the port.

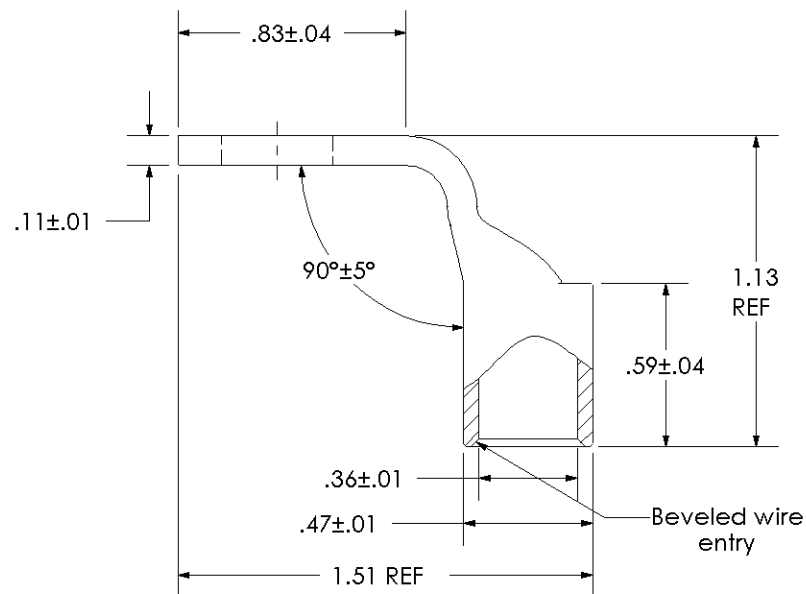

PANDUIT
BROWN DIE P33 (10)

- Color coded barrel markings

										
00	6/03	CJW	SAC	RELEASED	10850	LCAX2-38F-E Copper Lug - One-Hole, Standard Flex Barrel, 90° Angle Tongue				
REV	DATE	BY	CHK	DESCRIPTION	ECN	<table><tr><td>SCALE</td><td>DRAWING NO / CAD FILE</td></tr><tr><td>N/A</td><td>LCAX2-38F-CUST</td></tr></table>	SCALE	DRAWING NO / CAD FILE	N/A	LCAX2-38F-CUST
SCALE	DRAWING NO / CAD FILE									
N/A	LCAX2-38F-CUST									