


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	6 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/8 in.
Stud Size	#10
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLUE
Panduit Die Index No. on Barrel	P24
Alternate Industry Die Index No. () on Barrel	(7)

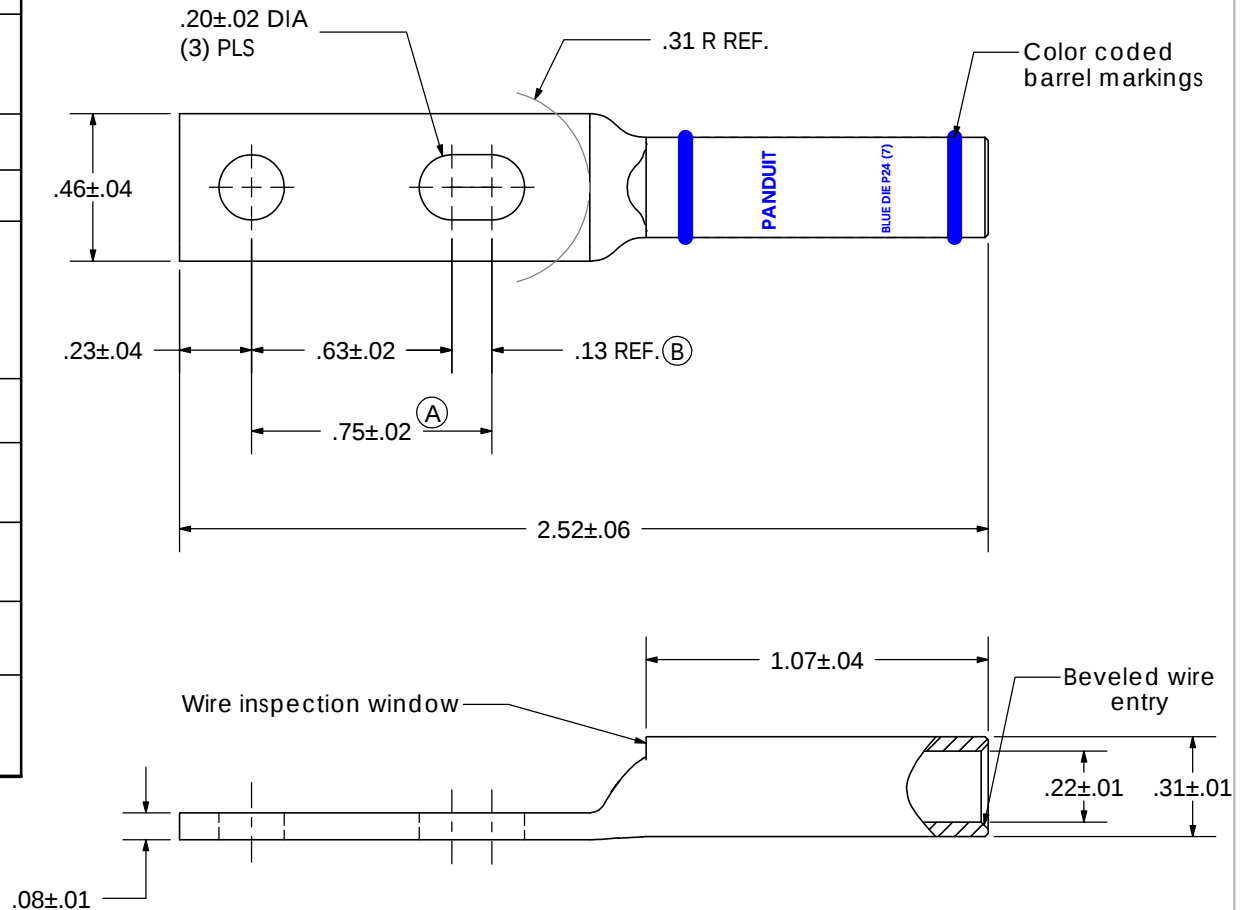

						PANDUIT CORP. TINLEY PARK, ILLINOIS	
						LCC6-10ABW-L	
						Copper Lug - Slotted Two-Hole, Long Barrel with Window	
01	2/05	JHNU	CSH	(A) ADDED DIMENSION (B) REMOVED TOLERANCE & ADDED REF. TO DIMENSION		12446	
REV	DATE	BY	CHK	DESCRIPTION		ECN	DRAWING NO / CAD FILE
						SCALE N/A	LCC6-10ABW-CUST