



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	6 AWG
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	BLUE
Panduit Die Index No. on Barrel	P24
Alternate Industry Die Index No. () on Barrel	(7)

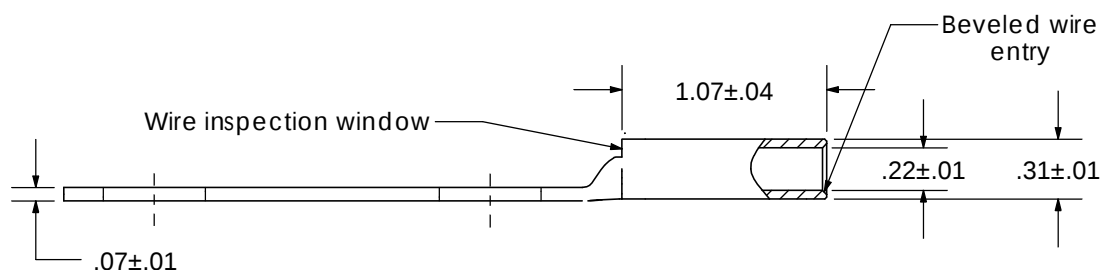

LISTED
Wire Connector

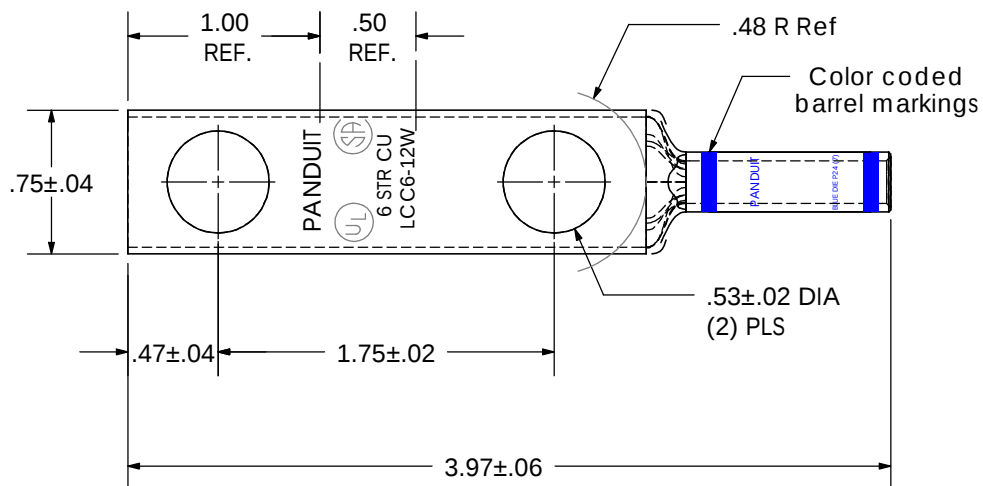

02	10/09	JESH	JESH	DIMENSION .47" +/- .04" WAS .50" +/- .04"			CORP. TINLEY PARK, ILLINOIS LCC6-12W-L Copper Lug - Two-Hole, Long Barrel with Window	
01	12/07	JESH	JESH	MOVED TEXT LOCATION TO CENTER OF PART				
				ADDED DIMENSIONS 1.00" REF., .50" REF.				
00	6/07	JHNU	LEM	RELEASED				
REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE N/A	DRAWING NO / CAD FILE LCC6-12W-CUST	