
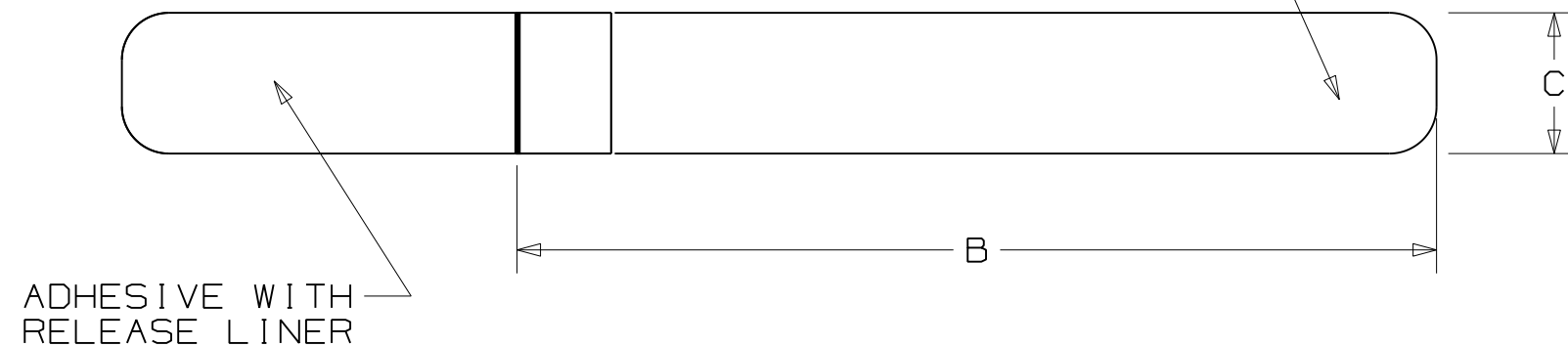
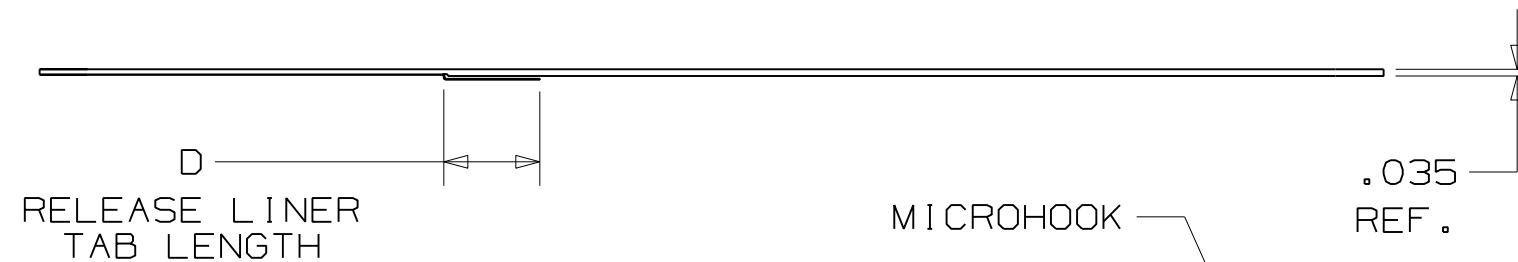


PANDUIT PART NO.	A	B (REF)	C	D (REF)	LOOP TENSILE
HLTT1.5S	7.00 (178)	5.02 (127.5)	.75 (19.0)	.5 (12.7)	30LBS MIN. (133 N)

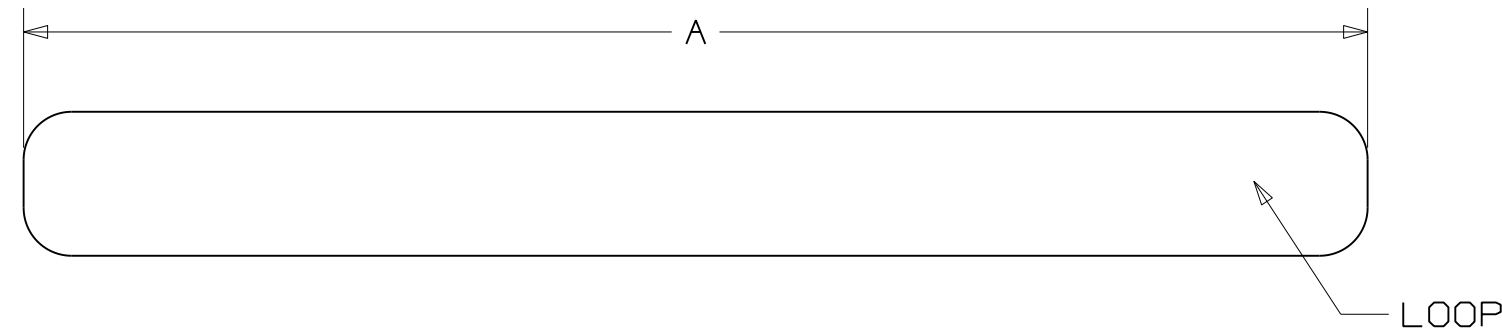

- NOTES :

1. COLOR: BLACK LOOP/NATURAL MICROHOOK
2. TEMP. LIMITS: 50C CONTINUOUS
3. RoHS COMPLIANT
4. SEE CURRENT PRICE SHEET FOR PART NUMBER
SUFFIX DESIGNATION FOR PACKAGE SIZE.
5. MINIMUM 2" OVERLAP REQUIRED TO ACHIEVE
LOOP TENSILE RATING.
6. LOOP: POLYAMIDE; MICROHOOK: POLYPROPYLENE;
ADHESIVE: REMOVABLE PRESSURE SENSITIVE
TYPE DESIGNED TO LEAVE NO RESIDUE ON
CABLE BUNDLE.
7. TABLE DIMS ARE IN.(MM).

[illegible]