

C-WM-A-WLHR Series

LED Wall Mount

Replaces 100W/120W Incandescent

C-LITE
LED LIGHTING BY CREE

POWERFUL, EFFICIENT & LONG LASTING LIGHT



PRODUCT SPECIFICATIONS

OVERVIEW

- Initial Delivered Lumens: 1,000, 1,200
- CRI: ≥ 70
- CCT: Neutral White (4000K)
- Mounting: Wall
- Input Power: 14 Watts, 22 Watts
- Dimmable: No
- Operating Minimum: -40°C (-40°F)
- Lifespan: 172,000 Hours (22W), 118,000 Hours (14W)
- Power Factor: > 0.95
- Total Harmonic Distortion: $< 20\%$
- Limited Warranty: 5 Years*
- Replaces 100W/120W Incandescent

RECOMMENDED USE	INPUT VOLTAGE
<ul style="list-style-type: none">• Security• Stairways• Perimeter Lighting	<ul style="list-style-type: none">• 120V Operation with built-in photocell

ORDERING INFORMATION

Example: C-WM-A-WLHR-10L-40K-MB

C-WM-A	WLHR		40K	
PRODUCT	STYLE	LUMEN PACKAGE	CCT	COLOR
C-WM-A	WLHR LED Wall Mount	10L 1,000 Lumens, 14W 12L 1,200 Lumens, 22W	40K Neutral White (4000K)	MB Medium Bronze WH White

CERTIFICATIONS:

US: c-lite.com T (800) 236-6800 F (262) 504-5415


Canada: www.cree.com/canada T (800) 473-1234 F (800) 890-7507

Rev. Date: V2 01/24/2018

For informational purposes only. Content is subject to change. *See lighting.cree.com/warranty for details



C-WM-A-WLHR Series

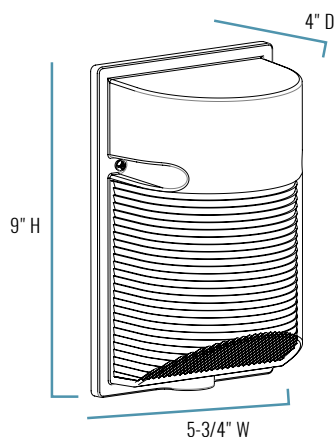

SERIES OVERVIEW

DIMENSIONS	PRODUCT WEIGHT	MOUNTING HEIGHT	SPACING
4" D x 5-3/4" W x 9" H	2.0 lbs.	8 to 12 feet	N/A

FIXTURE SPECIFICATIONS

HOUSING	Polycarbonate housing in medium bronze or white with heavy-duty aluminum mounting plate
LENS ASSEMBLY	UV-stabilized polycarbonate prismatic refractor
MOUNTING	1/2" NPT tapped knockout on bottom for conduit entry Knockout provided on back of housing for 1/2" conduit entry or mounts over 4" square or octagonal junction box

ELECTRICAL PERFORMANCE

OPERATING MINIMUM	LIFESPAN L ₇₀ AT 25°C (77°F)	POWER FACTOR	TOTAL HARMONIC DISTORTION	DIMMABLE
-40°C (-40°F)	172,000 Hours (22W) 118,000 Hours (14W)	> 0.95	< 20%	No
INPUT VOLTAGE	120V	208V	240V	277V
CURRENT DRAW (Amps)	0.12A (14W) 0.18A (22W)	N/A	N/A	N/A

WARRANTY AND CERTIFICATIONS

WARRANTY	UL LISTED
5 Year Limited*	Wet Locations

© 2018 Cree, Inc. and/or one of its subsidiaries. All rights reserved. For informational purposes only. Content is subject to change. Patent www.cree.com/patents. The CREE LEDs logo, C-LITE™ and the C-LITE logo are trademarks of Cree, Inc. The UL logo is a registered trademark of UL LLC.

US: c-lite.com T (800) 236-6800 F (262) 504-5415

Canada: www.cree.com/canada T (800) 473-1234 F (800) 890-7507

Rev. Date: V2 01/24/2018

For informational purposes only. Content is subject to change. *See lighting.cree.com/warranty for details

C-LITE
LED LIGHTING BY CREE