

DRAWING NO.
SE208074

7

6

5

4

3

2

1

REV

DATE

DESCRIPTION

ECO

BY

C'HECK.

J

2017-10-06 00:00:00 EDT

ADD YA442NTC58FXB TO SALES DRAWING SE..208074-01.

47796

BM

MB

CATALOG NUMBER

ACCOMMODATES

STUD SIZE

DIMENSIONS

CABLE STRIP LENGTH

INSTALLATION TOOLING

FLEXIBLE CABLE CODE AWG

B

C

C TOL.

E

K DIA.

L

N

P

T

Z MIN.

BELL

O.D.

DIELESS TOOLS

MECHANICAL HYTOOL™(CRIMPS)

HYDRAULIC HYPRESS™

DIE INDEX

COLOR CODE

DIE NUMBER (# OF CRIMPS)

Y35, Y39, Y750, Y46

YA8C2TC14FXB	#8 STR. (37/24) #8 AWG	1/4	.90 [23]	.44 [11]	±.04 [±1]	.62 [16]	.27 [7]	2.41 [61]	.31 [8]	1.06 [27]	.08 [2]	.33 [8]	.32 [8]	.27 [7]	1" [25]	MY29-3 (2) MY29-11 (2)	----	49	RED	U8CRT (2 CRIMPS)
YA8C2TC14E2FXB	#8 STR. (37/24) #8 AWG	1/4	.90 [23]	.44 [11]	±.04 [±1]	.75 [19]	.27 [7]	2.54 [65]	.31 [8]	1.06 [27]	.08 [2]	.33 [8]	.32 [8]	.27 [7]	1" [25]	MY29-3 (2) MY29-11 (2)	----	49	RED	U8CRT (2 CRIMPS)
YA8C2TC38FXB	#8 STR. (37/24) #8 AWG	3/8	.90 [23]	.58 [15]	±.05 [±1]	1.00 [25]	.40 [10]	2.98 [76]	.41 [10]	1.06 [27]	.06 [2]	.42 [11]	.32 [8]	.27 [7]	1" [25]	MY29-3 (2) MY29-11 (2)	----	49	RED	U8CRT (2 CRIMPS)
---	----	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	----	---	---	----
YAV6C2TC14FXB	#6 STR. (61/24) #6 AWG	1/4	1.22 [31]	.48 [12]	±.04 [±1]	.62 [16]	.27 [7]	2.76 [70]	.31 [8]	1.41 [36]	.08 [2]	.33 [8]	.37 [9]	.31 [8]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	7	BLUE	U5CRT (2 CRIMPS)
YAV6C2TC14E2FXB	#6 STR. (61/24) #6 AWG	1/4	1.22 [31]	.48 [12]	±.04 [±1]	.75 [19]	.27 [7]	2.88 [73]	.31 [8]	1.41 [36]	.08 [2]	.33 [8]	.37 [9]	.31 [8]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	7	BLUE	U5CRT (2 CRIMPS)
YAV6C2TC38FXB	#6 STR. (61/24) #6 AWG	3/8	1.22 [31]	.58 [15]	±.05 [±1]	1.00 [25]	.40 [10]	3.32 [84]	.41 [10]	1.41 [36]	.06 [2]	.42 [11]	.37 [9]	.31 [8]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	7	BLUE	U5CRT (2 CRIMPS)
YAV6C2NFXB	#6 STR. (61/24) #6 AWG	1/2	1.22 [31]	.83 [21]	±.04 [±1]	1.75 [44]	.56 [14]	4.51 [115]	.62 [16]	1.41 [36]	.12 [3]	.64 [16]	.37 [9]	.31 [8]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	7	BLUE	U5CRT (2 CRIMPS)
YAV6C2TC14E1FXB	#6 STR. (61/24) #6 AWG	1/4	1.22 [31]	.48 [12]	±.04 [±1]	1.00 [25]	.27 [7]	3.14 [80]	.31 [8]	1.41 [36]	.08 [2]	.33 [8]	.37 [9]	.31 [8]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	7	BLUE	U5CRT (2 CRIMPS)
YA5C2TC14FXB	#5 STR. (91/24) #5 AWG	1/4	1.22 [31]	.44 [11]	±.03 [±1]	.62 [16]	.27 [7]	2.76 [70]	.31 [8]	1.41 [36]	.07 [2]	.33 [8]	.35 [9]	.31 [8]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	7	BLUE	U5CRT (2 CRIMPS)

CONNECTOR RANGE

TOLERANCES

FROM	TO	B	E	K	L	N	P	BELL
#8 STR. (37/24) #8 AWG	1/0 STR. (275/24) 1/0 AWG	±.06	±.02	±.02	±.09	±.03	±.06	±.06
2/0 STR. (325/24) 2/0 AWG	373.3 kcmil (925/24) 350 kcmil NOM.	±.08	±.02	±.02	±.12	±.03	±.06	±.06
444.4 kcmil (1100/24) 450 kcmil NOM.	1111 kcmil (2750/24) 1000 kcmil NOM.	±.09	±.02	±.02	±.15	±.06	±.10	±.06

NOTES:

1. MATERIAL: COPPER.

2. FINISH: ELECTRO-TIN PLATED.

3. CATALOG NUMBER "PUADP-1" ADAPTOR IS REQUIRED TO USE "U" TYPE DIES IN THE Y46 SERIES TOOLS.

4. REFERENCE THE BURNDY® PRODUCTS MASTER CATALOG "INSTALLATION TOOL INDEX" FOR ADDITIONAL TOOLING.

5. BELLED BARREL ENDS PROVIDE EASY CABLE INSERTION AND STRAIN RELIEF.

6. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.

7. FOR UNDRILLED VERSIONS AND SUFFIX "U" TO END OF CATALOG NUMBER. FOR UNDRILLED VERSIONS,USE D MIN = N MAX + E MAX + Z MIN.

8. CONNECTORS ARE UL LISTED; UNDRILLED VERSIONS ARE NOT UL LISTED.

9. CONNECTORS ARE CSA CERTIFIED; UNDRILLED VERSIONS ARE NOT CSA CERTIFIED.

K DIA.
(2 PLCS)

9

TYPICAL LETTERING

YA8C-2TC14-FXB

BURNDY®

#8 STR.
37/24 CU

INDEX 49

BELL

8

N

E

C

Z MIN.

P

B

O.D.

L

T

TO ORDER BURNDY® PRODUCTS CALL

UNITED STATES

1-800-346-4175 (LONDONDERRY, NH)

CANADA:

1-800-361-6975 (QUEBEC)

1-800-387-6487 (ALL OTHER PROVINCES)

FOR PRODUCT INFO: <http://www.burndy.com>

TELECOM BELLED HYLUG™

ITEM NO: N/A

CAT. NO: YA-2-FXB- (TABLE)

DRAWN BY: J.GAUDET 11/04/92

CHECKER: K.HENRY 11/18/92

DSN APPVL: R.ROMAN 21/10/17

MFG APPVL: N/A --

QA APPVL: B.POST 11/10/17

MKT APPVL: B.MICHAUD 10/03/18

SCALE: NTS

DRAWING NO

 
 
 
REV

SE208074

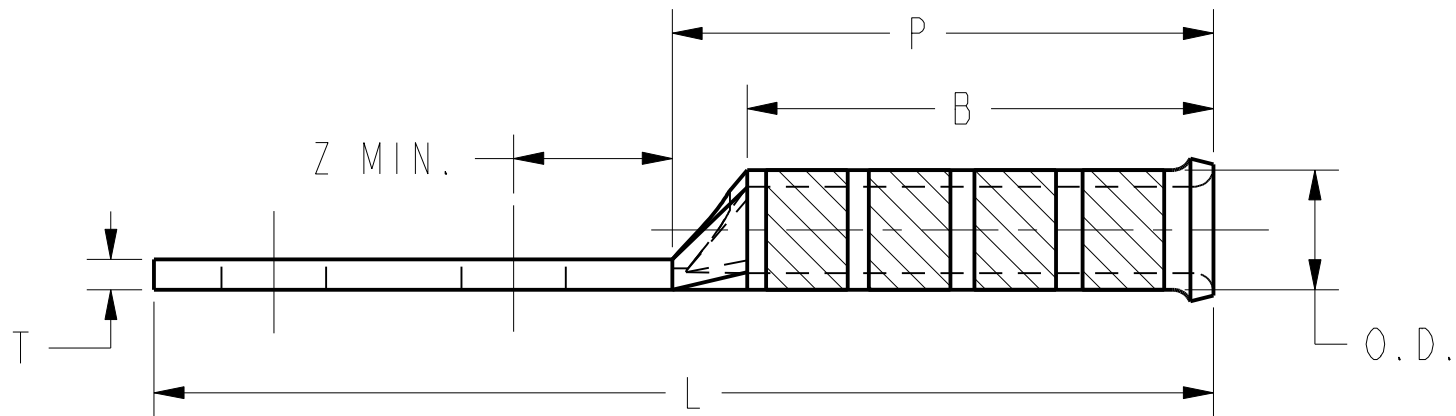
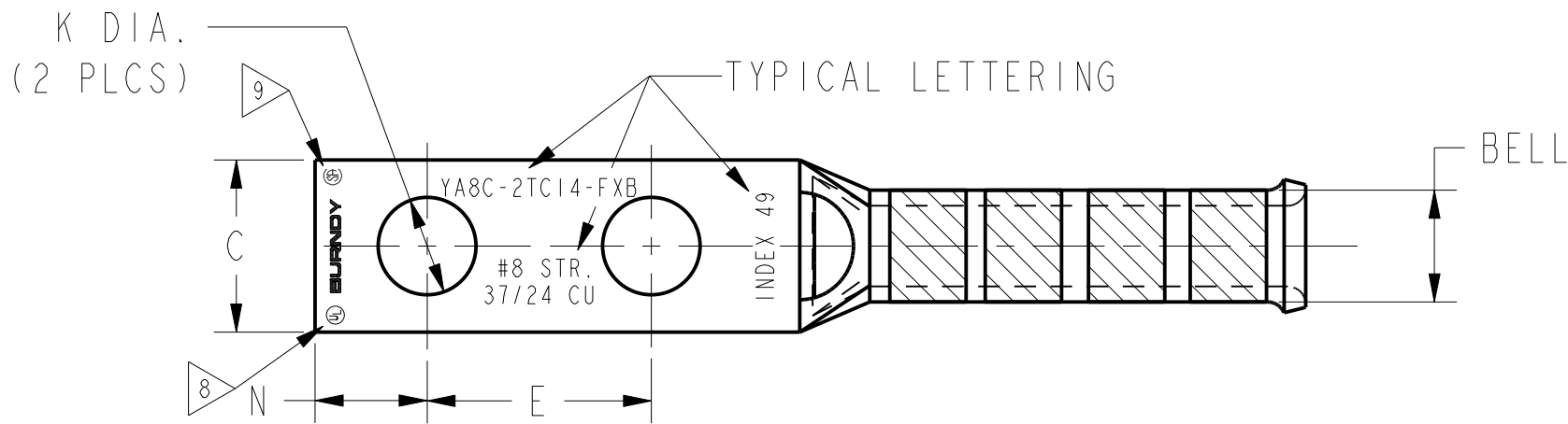
J

SHEET 1 OF 6

REV: PE0200

DRAWING NO. SE208074		7		6		5		4		3		2		1											
CATALOG NUMBER	ACCOMMODATES	STUD SIZE	DIMENSIONS												CABLE STRIP LENGTH	INSTALLATION TOOLING									
	FLEXIBLE CABLE CODE AWG		B	C	C TOL.	E 	K DIA.	L	N 	P	T	Z  MIN.	BELL	O.D.		DIELESS TOOLS		 Y35, Y39, Y750, PAT750,Y46,PAT46							
																MECHANICAL HYTOOL™(CRIMPS)	HYDRAULIC HYPRESS™	DIE INDEX	COLOR CODE	DIE NUMBER (# OF CRIMPS)					
YAV4C2TC14FXB	#4 STR. (91/24-105/24) #4 AWG	1/4	1.22 [31]	.55 [14]	±.03 [±1]	.62 [16]	.27 [7]	2.81 [71]	.31 [8]	1.46 [37]	.09 [2]	.33 [8]	.44 [11]	.38 [10]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	8	GRAY	U4CRT (2 CRIMPS)					
YAV4C2TC14E2FXB	#4 STR. (91/24-105/24) #4 AWG	1/4	1.22 [31]	.55 [14]	±.03 [±1]	.75 [19]	.27 [7]	2.93 [74]	.31 [8]	1.46 [37]	.09 [2]	.33 [8]	.44 [11]	.38 [10]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	8	GRAY	U4CRT (2 CRIMPS)					
YAV4C2TC14E1FXB	#4 STR. (91/24-105/24) #4 AWG	1/4	1.22 [31]	.55 [14]	±.03 [±1]	1.00 [25]	.27 [7]	3.18 [81]	.31 [8]	1.46 [37]	.09 [2]	.33 [8]	.44 [11]	.38 [10]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	8	GRAY	U4CRT (2 CRIMPS)					
YAV4C2TC516FXB	#4 STR. (91/24-105/24) #4 AWG	5/16	1.22 [31]	.55 [14]	±.03 [±1]	1.00 [25]	.33 [8]	3.24 [82]	.34 [9]	1.46 [37]	.09 [2]	.36 [9]	.44 [11]	.38 [10]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	8	GRAY	U4CRT (2 CRIMPS)					
YAV4C2TC38FXB	#4 STR. (91/24-105/24) #4 AWG	3/8	1.22 [31]	.58 [15]	±.04 [±1]	1.00 [25]	.41 [10]	3.37 [86]	.41 [10]	1.46 [37]	.09 [2]	.42 [11]	.44 [11]	.38 [10]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	8	GRAY	U4CRT (2 CRIMPS)					
YAV4C2NFXB	#4 STR. (91/24-105/24) #4 AWG	1/2	1.22 [31]	.83 [21]	±.04 [±1]	1.75 [44]	.56 [14]	4.56 [116]	.62 [16]	1.46 [37]	.12 [3]	.64 [16]	.44 [11]	.38 [10]	1-5/16" [33]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	8	GRAY	U4CRT (2 CRIMPS)					
---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---					
YAV3C2TC516FXB	#3 STR. (105/24-125/24) #3 AWG	5/16	1.48 [38]	.60 [15]	±.03 [1]	1.00 [25]	.33 [8]	3.51 [89]	.34 [9]	1.73 [44]	.09 [2]	.36 [9]	.49 [12]	.42 [11]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	9	WHITE	U3CRT (2 CRIMPS)					
YAV3C2TC38FXB	#3 STR. (105/24-125/24) #3 AWG	3/8	1.48 [38]	.60 [15]	±.04 [1]	1.00 [25]	.41 [10]	3.64 [92]	.41 [10]	1.73 [44]	.09 [2]	.42 [11]	.49 [12]	.42 [11]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	9	WHITE	U3CRT (2 CRIMPS)					
YAV3C2NFXB	#3 STR. (105/24-125/24) #3 AWG	1/2	1.48 [38]	.83 [21]	±.04 [1]	1.75 [44]	.56 [14]	4.83 [123]	.62 [16]	1.73 [44]	.12 [3]	.64 [16]	.49 [12]	.42 [11]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	9	WHITE	U3CRT (2 CRIMPS)					
---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---					
YAV2C2TC14FXB	#2 STR. (125/24-150/24) #2 AWG	1/4	1.35 [34]	.68 [17]	±.03 [1]	.62 [16]	.27 [7]	3.00 [76]	.31 [8]	1.65 [42]	.10 [3]	.33 [8]	.54 [14]	.46 [12]	1-7/16 [37]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	10	BROWN	U2CRT (2 CRIMPS)					
YAV2C2TC14E2FXB	#2 STR. (125/24-150/24) #2 AWG	1/4	1.35 [34]	.68 [17]	±.03 [1]	.75 [19]	.27 [7]	3.13 [79]	.31 [8]	1.65 [42]	.10 [3]	.33 [8]	.54 [14]	.46 [12]	1-7/16 [37]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	10	BROWN	U2CRT (2 CRIMPS)					
YAV2C2TC14E1FXB	#2 STR. (125/24-150/24) #2 AWG	1/4	1.35 [34]	.68 [17]	±.03 [1]	1.00 [25]	.27 [7]	3.38 [86]	.31 [8]	1.65 [42]	.10 [3]	.33 [8]	.54 [14]	.46 [12]	1-7/16 [37]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	10	BROWN	U2CRT (2 CRIMPS)					
YAV2C2TC516FXB	#2 STR. (125/24-150/24) #2 AWG	5/16	1.35 [34]	.68 [17]	±.03 [1]	1.00 [25]	.33 [8]	3.44 [87]	.34 [9]	1.65 [42]	.10 [3]	.36 [9]	.54 [14]	.46 [12]	1-7/16 [37]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	10	BROWN	U2CRT (2 CRIMPS)					
YAV2C2TC38FXB	#2 STR. (125/24-150/24) #2 AWG	3/8	1.35 [34]	.68 [17]	±.03 [1]	1.00 [25]	.41 [10]	3.57 [91]	.41 [10]	1.65 [42]	.10 [3]	.42 [11]	.54 [14]	.46 [12]	1-7/16 [37]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	10	BROWN	U2CRT (2 CRIMPS)					
YAV2C2NT38FXB	#2 STR. (125/24-150/24) #2 AWG	3/8	1.35 [34]	.55 [14]	±.03 [1]	1.00 [25]	.41 [10]	3.57 [91]	.41 [10]	1.65 [42]	.10 [3]	.42 [11]	.54 [14]	.46 [12]	1-7/16 [37]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	10	BROWN	U2CRT (2 CRIMPS)					
YAV2C2NFXB	#2 STR. (125/24-150/24) #2 AWG	1/2	1.35 [34]	.83 [21]	±.04 [1]	1.75 [44]	.56 [14]	4.76 [121]	.62 [16]	1.65 [42]	.12 [3]	.64 [16]	.54 [14]	.46 [12]	1-7/16 [37]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	10	BROWN	U2CRT (2 CRIMPS)					
---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---					
YAV1C2TC14FXB	#1 STR. (175/24-225/24) #1 AWG	1/4	1.50 [38]	.75 [19]	±.03 [1]	.62 [16]	.27 [7]	3.17 [81]	.31 [8]	1.82 [46]	.12 [3]	.33 [8]	.60 [15]	.51 [13]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	11	GREEN	U1CRT-1 (2 CRIMPS)					
YAV1C2TC14E2FXB	#1 STR. (175/24-225/24) #1 AWG	1/4	1.50 [38]	.75 [19]	±.03 [1]	.75 [19]	.27 [7]	3.30 [84]	.31 [8]	1.82 [46]	.12 [3]	.33 [8]	.60 [15]	.51 [13]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	11	GREEN	U1CRT-1 (2 CRIMPS)					
YAV1C2TC38FXB	#1 STR. (175/24-225/24) #1 AWG	3/8	1.50 [38]	.75 [19]	±.03 [1]	1.00 [25]	.41 [10]	3.74 [95]	.41 [10]	1.82 [46]	.12 [3]	.42 [11]	.60 [15]	.51 [13]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	11	GREEN	U1CRT-1 (2 CRIMPS)					
YAV1C2NFXB	#1 STR. (175/24-225/24) #1 AWG	1/2	1.50 [38]	.83 [21]	±.04 [1]	1.75 [44]	.56 [14]	4.92 [125]	.62 [16]	1.82 [46]	.11 [3]	.64 [16]	.60 [15]	.51 [13]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	11	GREEN	U1CRT-1 (2 CRIMPS)					
NOTES:																					SEE SHEET ONE FOR VIEWS				
1. MATERIAL: COPPER.																									
2. FINISH: TIN PLATED.																									
 CATALOG NUMBER "PUADP-1" ADAPTOR IS REQUIRED TO USE "U" TYPE DIES IN THE Y46 SERIES TOOLS.																									
4. REFERENCE THE BURNDY® MASTER CATALOG "INSTALLATION TOOL INDEX" FOR ADDITIONAL TOOLING.																					TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES) FOR PRODUCT INFO: http://www.burndy.com				
5. BELLED BARREL ENDS PROVIDE EASY CABLE INSERTION AND STRAIN RELIEF.																									
6. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.																									
 FOR UNDRILLED VERSIONS AND SUFFIX "U" TO END OF CATALOG NUMBER. FOR UNDRILLED VERSIONS,USE D MIN = N MAX + E MAX + Z MIN.																									
 CONNECTORS ARE UL LISTED; UNDRILLED VERSIONS ARE NOT UL LISTED.																									
 CONNECTORS ARE CSA CERTIFIED; UNDRILLED VERSIONS ARE NOT CSA CERTIFIED.																									
REV												DATE		DESCRIPTION				ECO	BY	C'H'K.	TELECOM BELLED HYLUG™				
J												2017-10-06 00:00:00 EDT		ADD Y442NTC58FXB TO SALES DRAWING SE1.208074-01.				47796	BM	MB	ITEM NO: N/A CAT. NO: YA-2-FXB- (TABLE) DRAWN BY: J.GAUDET 11/04/92 CHECKER: K.HENRY 11/18/92 DSN APPVL: C.PALAGI 11/20/92 MFG APPVL: N/A -- QA APPVL: A.LLOYD 11/22/92 MKT APPVL: L.HERRON 11/23/92 PROD FAM: -- PROJECT #: FPN1512073 DOCUMENT TYPE: Sales REL LEVEL: Released				
																					SCALE: NTS DRAWING NO REV				
																					SHEET 2 OF 6				

DRAWING NO. SE208074		7		6		5		4		3		2		1						
CATALOG NUMBER	ACCOMMODATES	STUD SIZE	DIMENSIONS												CABLE STRIP LENGTH	INSTALLATION TOOLING				
	FLEXIBLE CABLE CODE AWG		B	C	C TOL.	E	K DIA.	L	N	P	T	Z MIN.	BELL	O.D.		DIELESS TOOLS		Y35, Y39, Y750, Y46		
																MECHANICAL HYTOOL™(CRIMPS)	HYDRAULIC HYPRESS™	DIE INDEX	COLOR CODE	DIE NUMBER (# OF CRIMPS)
YAV252TC14FXB	1/0 STR. (275/24) 1/0 AWG	1/4	1.50 [38]	.83 [21]	±.03 [1]	.62 [16]	.27 [7]	3.21 [82]	.31 [8]	1.86 [47]	.12 [3]	.33 [8]	.66 [17]	.56 [14]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	12	PINK	U25RT (2 CRIMPS)
YAV252TC14E2FXB	1/0 STR. (275/24) 1/0 AWG	1/4	1.50 [38]	.83 [21]	±.03 [1]	.75 [19]	.27 [7]	3.34 [85]	.31 [8]	1.86 [47]	.12 [3]	.33 [8]	.66 [17]	.56 [14]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	12	PINK	U25RT (2 CRIMPS)
YAV252TC38FXB	1/0 STR. (275/24) 1/0 AWG	3/8	1.50 [38]	.83 [21]	±.03 [1]	1.00 [25]	.40 [10]	3.78 [96]	.41 [10]	1.86 [47]	.12 [3]	.42 [11]	.66 [17]	.56 [14]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	12	PINK	U25RT (2 CRIMPS)
YAV252NTC38FXB	1/0 STR. (275/24) 1/0 AWG	3/8	1.50 [38]	.83 [21]	±.03 [1]	1.75 [44]	.40 [10]	4.53 [115]	.41 [10]	1.86 [47]	.12 [3]	.42 [11]	.66 [17]	.56 [14]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	12	PINK	U25RT (2 CRIMPS)
YAV252NFXB	1/0 STR. (275/24) 1/0 AWG	1/2	1.50 [38]	.83 [21]	±.03 [1]	1.75 [44]	.56 [14]	4.96 [126]	.62 [16]	1.86 [47]	.12 [3]	.64 [16]	.66 [17]	.56 [14]	1-9/16 [40]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	12	PINK	U25RT (2 CRIMPS)
---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---
YAV262TC14FXB	2/0 STR. (325/24) 2/0 AWG	1/4	1.63 [41]	.93 [24]	±.03 [1]	.62 [16]	.27 [7]	3.40 [86]	.31 [8]	2.05 [52]	.13 [3]	.33 [8]	.74 [19]	.63 [16]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	13	BLACK	U26RT (2 CRIMPS)
YAV262TC14E2FXB	2/0 STR. (325/24) 2/0 AWG	1/4	1.63 [41]	.93 [24]	±.03 [1]	.75 [19]	.27 [7]	3.52 [89]	.31 [8]	2.05 [52]	.13 [3]	.33 [8]	.74 [19]	.63 [16]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	13	BLACK	U26RT (2 CRIMPS)
YAV262TC38FXB	2/0 STR. (325/24) 2/0 AWG	3/8	1.63 [41]	.93 [24]	±.03 [1]	1.00 [25]	.40 [10]	3.96 [101]	.41 [10]	2.05 [52]	.13 [3]	.42 [11]	.74 [19]	.63 [16]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	13	BLACK	U26RT (2 CRIMPS)
YAV262NTC38FXB	2/0 STR. (325/24) 2/0 AWG	3/8	1.63 [41]	.93 [24]	±.03 [1]	1.75 [44]	.40 [10]	4.71 [120]	.41 [10]	2.05 [52]	.13 [3]	.42 [11]	.74 [19]	.63 [16]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	13	BLACK	U26RT (2 CRIMPS)
YAV262TC38E11FXB	2/0 STR. (325/24) 2/0 AWG	3/8	1.63 [41]	.93 [24]	±.03 [1]	2.00 [51]	.41 [10]	4.96 [126]	.41 [10]	2.05 [52]	.13 [3]	.42 [11]	.74 [19]	.63 [16]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	13	BLACK	U26RT (2 CRIMPS)
YAV262NFXB	2/0 STR. (325/24) 2/0 AWG	1/2	1.63 [41]	.93 [24]	±.03 [1]	1.75 [44]	.56 [14]	5.15 [131]	.62 [16]	2.05 [52]	.13 [3]	.64 [16]	.74 [19]	.63 [16]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	13	BLACK	U26RT (2 CRIMPS)
YAV272TC14E2FXB	3/0 STR. (450/24) 3/0 AWG	1/4	1.64 [42]	1.03 [26]	±.04 [1]	.75 [19]	.27 [7]	3.58 [91]	.31 [8]	2.10 [53]	.14 [4]	.33 [8]	.82 [21]	.70 [18]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	14	ORANGE	U27RT (2 CRIMPS)
YAV272TC38FXB	3/0 STR. (450/24) 3/0 AWG	3/8	1.64 [42]	1.03 [26]	±.04 [1]	1.00 [25]	.40 [10]	4.01 [102]	.41 [10]	2.10 [53]	.14 [4]	.42 [11]	.82 [21]	.70 [18]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	14	ORANGE	U27RT (2 CRIMPS)
YAV272NFXB	3/0 STR. (450/24) 3/0 AWG	1/2	1.64 [42]	1.03 [26]	±.04 [1]	1.75 [44]	.56 [14]	5.20 [132]	.62 [16]	2.10 [53]	.14 [4]	.64 [16]	.82 [21]	.70 [18]	1-13/16 [46]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	14	ORANGE	U27RT (2 CRIMPS)
---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---
YAV282TC14E2FXB	4/0 STR. (550/24) 4/0 AWG	1/4	1.77 [45]	1.14 [29]	±.04 [1]	.75 [19]	.27 [7]	3.76 [96]	.31 [8]	2.28 [58]	.14 [4]	.33 [8]	.90 [23]	.77 [20]	1-7/8 [48]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	15	PURPLE	U28RT (2 CRIMPS)
YAV282NT516FXB	4/0 STR. (550/24) 4/0 AWG	5/16	1.77 [45]	1.14 [29]	±.04 [1]	1.75 [44]	.33 [8]	4.82 [122]	.34 [9]	2.28 [58]	.14 [4]	.36 [9]	.90 [23]	.77 [20]	1-7/8 [48]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	15	PURPLE	U28RT (2 CRIMPS)
YAV282NT38FXB	4/0 STR. (550/24) 4/0 AWG	3/8	1.77 [45]	.75 [19]	±.04 [1]	1.00 [25]	.40 [10]	4.20 [107]	.41 [10]	2.28 [58]	.14 [4]	.42 [11]	.90 [23]	.77 [20]	1-7/8 [48]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	15	PURPLE	U28RT (2 CRIMPS)
YAV282TC38FXB	4/0 STR. (550/24) 4/0 AWG	3/8	1.77 [45]	1.14 [29]	±.04 [1]	1.00 [25]	.40 [10]	4.20 [107]	.41 [10]	2.28 [58]	.14 [4]	.42 [11]	.90 [23]	.77 [20]	1-7/8 [48]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	15	PURPLE	U28RT (2 CRIMPS)
YAV282TC12FXB	4/0 STR. (550/24) 4/0 AWG	1/2	1.77 [45]	1.14 [29]	±.04 [1]	1.25 [32]	.56 [14]	4.70 [119]	.53 [13]	2.28 [58]	.14 [4]	.42 [11]	.90 [23]	.77 [20]	1-7/8 [48]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	15	PURPLE	U28RT (2 CRIMPS)
YAV282NTC38FXB	4/0 STR. (550/24) 4/0 AWG	3/8	1.77 [45]	1.14 [29]	±.04 [1]	1.75 [44]	.40 [10]	4.20 [107]	.41 [10]	2.28 [58]	.14 [4]	.42 [11]	.90 [23]	.77 [20]	1-7/8 [48]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	15	PURPLE	U28RT (2 CRIMPS)
YAV282NFXB	4/0 STR. (550/24) 4/0 AWG	1/2	1.77 [45]	1.14 [29]	±.04 [1]	1.75 [44]	.56 [13]	5.39 [137]	.62 [16]	2.28 [58]	.14 [4]	.64 [16]	.90 [23]	.77 [20]	1-7/8 [48]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	15	PURPLE	U28RT (2 CRIMPS)
YAV292TC14E2FXB	4/0 FLEX CLASS I, K, M	1/4	2.16 [55]	1.18 [30]	±.04 [1]	.75 [19]	.27 [7]	4.19 [106]	.31 [8]	2.70 [69]	.16 [4]	.33 [8]	.94 [24]	.80 [20]	2-1/4 [57]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	16	YELLOW	U29RT (2 CRIMPS)
YAV292NT38FXB	4/0 FLEX CLASS I, K, M	3/8	2.16 [55]	.75 [19]	±.04 [1]	1.00 [25]	.40 [10]	4.62 [117]	.41 [10]	2.70 [69]	.16 [4]	.42 [11]	.94 [24]	.80 [20]	2-1/4 [57]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	16	YELLOW	U29RT (2 CRIMPS)
YAV292TC38FXB	4/0 FLEX CLASS I, K, M	3/8	2.16 [55]	1.18 [30]	±.04 [1]	1.00 [25]	.40 [10]	4.62 [117]	.41 [10]	2.70 [69]	.16 [4]	.42 [11]	.94 [24]	.80 [20]	2-1/4 [57]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	16	YELLOW	U29RT (2 CRIMPS)
YAV292NTC38FXB	4/0 FLEX CLASS I, K, M	3/8	2.16 [55]	1.18 [30]	±.04 [1]	1.75 [44]	.40 [10]	5.37 [136]	.41 [10]	2.70 [69]	.16 [4]	.42 [11]	.94 [24]	.80 [20]	2-1/4 [57]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	16	YELLOW	U29RT (2 CRIMPS)
YAV292NFXB	4/0 FLEX CLASS I, K, M	1/2	2.16 [55]	1.18 [30]	±.04 [1]	1.75 [44]	.56 [14]	5.81 [148]	.62 [16]	2.70 [69]	.16 [4]	.64 [16]	.94 [24]	.80 [20]	2-1/4 [57]	MY29-3 (2) MY29-11 (2)	Y644M (1 CRIMP)	16	YELLOW	U29RT (2 CRIMPS)
NOTES:																				
1. MATERIAL: COPPER.																				
2. FINISH: ELECTRO-TIN PLATED.																				
3 CATALOG NUMBER "PUADP-1" ADAPTOR IS REQUIRED TO USE "U" TYPE DIES IN THE Y46 SERIES TOOLS.																				
4. REFERENCE THE BURNDY® PRODUCTS MASTER CATALOG "INSTALLATION TOOL INDEX" FOR ADDITIONAL TOOLING.																				
5. BELLED BARREL ENDS PROVIDE EASY CABLE INSERTION AND STRAIN RELIEF.																				
6. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.																				
7 FOR UNDRILLED VERSIONS AND SUFFIX "U" TO END OF CATALOG NUMBER. FOR UNDRILLED VERSIONS,USE D MIN = N MAX + E MAX + Z MIN.																				
8 CONNECTORS ARE UL LISTED; UNDRILLED VERSIONS ARE NOT UL LISTED.																				
9 CONNECTORS ARE CSA CERTIFIED; UNDRILLED VERSIONS ARE NOT CSA CERTIFIED.																				
10 FOR "OIL TIGHT" SEAL ADD SUFFIX "DT" TO END OF CATALOG NUMBER.																				
REV J 2017-10-06 00:00:00 EDT ADD YA442NTC58FXB TO SALES DRAWING SE..208074-01.47796 BM MB												ECO BY C'H'K. 47796 BM MB								
TO ORDER BURNDY® PRODUCTS CALL												UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)								
CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)												FOR PRODUCT INFO: http://www.burndy.com								
HYLUG™ BELLED, TELECOM												ITEM NO: N/A								
CAT. NO: YA-2-FXB- (TABLE)												DRAWN BY: J GAUDET 11/6/92								
CHECKER: K HENDRY 11/18/92												DSN APPVL: C PALAGI 11/20/92								
MFG APPVL: -- --												QA APPVL: A LLOYD 11/21/92								
MKT APPVL: L HERRON 11/23/92												SCALE: NTS								
PROD FAM: --												PROJECT #: --								
DOCUMENT TYPE: Sales												SIZE D								
REL LEVEL: Released												DRAWING NO SE208074								
												SHEET 3 OF 6								
												REV J								



TO ORDER BURNDY® PRODUCTS CALL				HYLUG™ BELLED, TELECOM					
UNITED STATES				ITEM NO: N/A					
1-800-346-4175 (LONDONDERRY, NH)				CAT. NO: YA-2-FXB- (TABLE)					
CANADA:				DRAWN BY: J GAUDET 11/76/92					
1-800-361-6975 (QUEBEC)				CHECKER: K HENDRY 11/18/92					
1-800-387-6487 (ALL OTHER PROVINCES)				DSN APPVL: C PALAGI 11/20/92					
FOR PRODUCT INFO: http://www.burndy.com				MFG APPVL: -- --					
				QA APPVL: A LLOYD 11/21/92					
				MKT APPVL: L HERRON 11/23/92					
				SCALE: NTS					
				PROD FAM: --		DRAWING NO		REV	
				PROJECT #: --		SIZE		J	
				DOCUMENT TYPE: Sales		D		SE208074	
				REL LEVEL: Released				SHEET 3 OF 6	

DRAWING NO. SE208074		7				6				5				4				3				2				1											
																				REV	DATE			DESCRIPTION										ECO	BY	C' H' K.	
																				J	2017-10-06 00:00:00 EDT			ADD YAA42NTCS8FXB TO SALES DRAWING SE.,208074-01.										47796	BM	MB	
D	CATALOG NUMBER	ACCOMMODATES	STUD SIZE	DIMENSIONS												CABLE STRIP LENGTH	INSTALLATION TOOLING																				
														DIELESS TOOLS			3 Y35, Y39, Y750, Y46																				
		FLEXIBLE CABLE CODE AWG	B	C	C TOL.	E	K DIA.	L	N	P	T	Z MIN.	BELL	O.D.	MECHANICAL HYTOOL™		HYDRAULIC HYPRESSTM	DIE INDEX	COLOR CODE	DIE NUMBER (# OF CRIMPS)																	
	"CONNECTORS BELOW ARE FOR FLEXIBLE CONDUCTOR ONLY"																																				
	YA302TC38FXB	250 Kcmil FLEX CLASS G 259 STR. CLASS M 427 STR.	3/8	2.16 [55]	1.20 [30]	±.04 [1]	1.00 [25]	.40 [10]	4.61 [117]	.41 [10]	2.70 [69]	.16 [4]	.42 [11]	.95 [24]	.81 [21]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	16	YELLOW	U29RT (2 CRIMPS)															
	YA302NFXB	250 Kcmil FLEX CLASS G 259 STR. CLASS M 427 STR.	1/2	2.16 [55]	1.20 [30]	±.04 [1]	1.75 [44]	.56 [14]	5.80 [147]	.62 [16]	2.70 [69]	.16 [4]	.64 [16]	.95 [24]	.81 [21]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	16	YELLOW	U29RT (2 CRIMPS)															
	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---															
C	YA312TC38FXB	263 Kcmil (650/24) 250 FLEX CLASS I, K, M	3/8	2.18 [55]	1.29 [33]	±.04 [1]	1.00 [25]	.40 [10]	4.66 [118]	.41 [10]	2.75 [70]	.18 [5]	.42 [11]	1.03 [26]	.88 [22]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	17	WHITE	U30RT (4 CRIMPS)															
	YA312NTC38FXB	263 Kcmil (650/24) 250 FLEX CLASS I, K, M	3/8	2.18 [55]	1.29 [33]	±.04 [1]	1.75 [44]	.40 [10]	5.41 [137]	.41 [10]	2.75 [70]	.18 [5]	.42 [11]	1.03 [26]	.88 [22]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	17	WHITE	U30RT (4 CRIMPS)															
	YA312NFXB	263 Kcmil (650/24) 250 FLEX CLASS I, K, M	1/2	2.18 [55]	1.29 [33]	±.04 [1]	1.75 [44]	.56 [14]	5.85 [149]	.62 [16]	2.75 [70]	.18 [5]	.64 [16]	1.03 [26]	.88 [22]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	17	WHITE	U30RT (4 CRIMPS)															
	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---															
	YA322TC38FXB	313.1 Kcmil (775/24)	3/8	2.32 [60]	1.40 [36]	±.04 [1]	1.00 [25]	.40 [10]	4.85 [123]	.41 [10]	2.94 [75]	.19 [5]	.42 [11]	1.12 [28]	.95 [24]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	18	RED	U31RT (4 CRIMPS)															
	YA322NTC38FXB	313.1 Kcmil (775/24)	3/8	2.32 [60]	1.40 [36]	±.04 [1]	1.75 [44]	.40 [10]	5.60 [142]	.41 [10]	2.94 [75]	.19 [5]	.42 [11]	1.12 [28]	.95 [24]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	18	RED	U31RT (4 CRIMPS)															
	YA322NFXB	313.1 Kcmil (775/24)	1/2	2.32 [60]	1.40 [36]	±.04 [1]	1.75 [44]	.56 [14]	6.04 [153]	.62 [16]	2.94 [75]	.19 [5]	.64 [16]	1.12 [28]	.95 [24]	2-1/4 [57]	---	---	Y644M (1 CRIMP)	18	RED	U31RT (4 CRIMPS)															
	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---															
B	YA342TC14E2FXB	373.7 Kcmil (925/24)	1/4	2.48 [63]	1.55 [39]	±.04 [1]	.75 [19]	.27 [7]	4.66 [118]	.31 [8]	3.17 [81]	.23 [6]	.33 [8]	1.24 [31]	1.06 [27]	2-9/16 [65]	---	---	Y644M (1 CRIMP)	19	BLUE	U32RT (4 CRIMPS)															
	YA342TC38FXB	373.7 Kcmil (925/24)	3/8	2.48 [63]	1.55 [39]	±.04 [1]	1.00 [25]	.40 [10]	5.10 [130]	.41 [10]	3.17 [81]	.23 [6]	.42 [11]	1.24 [31]	1.06 [27]	2-9/16 [65]	---	---	Y644M (1 CRIMP)	19	BLUE	U32RT (4 CRIMPS)															
	YA342NFXB	373.7 Kcmil (925/24)	1/2	2.48 [63]	1.55 [39]	±.04 [1]	1.75 [44]	.56 [14]	6.29 [160]	.62 [16]	3.17 [81]	.23 [6]	.64 [16]	1.24 [31]	1.06 [27]	2-9/16 [65]	---	---	Y644M (1 CRIMP)	19	BLUE	U32RT (4 CRIMPS)															
	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---															
	YA362TC38FXB	444.4 Kcmil (1100/24)	3/8	2.95 [75]	1.73 [44]	±.06 [2]	1.00 [25]	.40 [10]	5.84 [148]	.50 [13]	3.72 [94]	.26 [7]	.52 [13]	1.40 [36]	1.18 [30]	3-1/16 [78]	---	---	Y644M (1 CRIMP)	20	BROWN	U34RT (4 CRIMPS)															
	YA362NFXB	444.4 Kcmil (1100/24)	1/2	2.95 [75]	1.73 [44]	±.06 [2]	1.75 [44]	.56 [14]	6.84 [174]	.62 [16]	3.72 [94]	.26 [7]	.64 [16]	1.40 [36]	1.18 [30]	3-1/16 [78]	---	---	Y644M (1 CRIMP)	20	BROWN	U34RT (4 CRIMPS)															
	NOTES:																																				
	1. MATERIAL: COPPER.																																				
2. FINISH: TIN PLATED.																																					
3 CATALOG NUMBER "PUADP-1" ADAPTOR IS REQUIRED TO USE "U" TYPE DIES IN THE Y46 SERIES TOOLS.																																					
4. REFERENCE THE BURNDY® PRODUCTS MASTER CATALOG "INSTALLATION TOOL INDEX" FOR ADDITIONAL TOOLING.																																					
5. BELLED BARREL ENDS PROVIDE EASY CABLE INSERTION AND STRAIN RELIEF.																																					
6. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.																																					
7 FOR UNDRILLED VERSIONS AND SUFFIX "U" TO END OF CATALOG NUMBER. FOR UNDRILLED VERSIONS,USE D MIN = N MAX + E MAX + Z MIN.																																					
8 CONNECTORS ARE UL LISTED; UNDRILLED VERSIONS ARE NOT UL LISTED.																																					
9 CONNECTORS ARE CSA CERTIFIED; UNDRILLED VERSIONS ARE NOT CSA CERTIFIED.																																					
TO ORDER BURNDY® PRODUCTS CALL																		TELECOM BELLED HYLUG™																			
UNITED STATES																		ITEM NO: N/A																			
1-800-346-4175 (LONDONDERRY, NH)																		CAT. NO: YA-2-FXB- (TABLE)																			
CANADA:																		DRAWN BY: M.PITTENDREIGH 8/02/93																			
1-800-361-6975 (QUEBEC)																		CHECKER: R.ROBICHEAU 8/10/93																			
1-800-387-6487 (ALL OTHER PROVINCES)																		DSN APPVL: C.PALAGI 8/11/93																			
FOR PRODUCT INFO: http://www.burndy.com																		MFG APPVL: N/A --																			
																		QA APPVL: A.LLOYD 8/31/93																			
																		MKT APPVL: M.BLAKE 8/26/93																			
																		PROD. FAM: --		DRAWING NO		REV															
																		PROJECT #: --		SIZE		SE208074															
																		DOCUMENT TYPE: Sales		D		J															
																		REL. LEVEL: Released				SHEET 4 OF 6															

REV.: PE0200



DRAWING NO. SE208074		7		6		5		4		3		2		1							
CATALOG NUMBER	ACCOMMODATES	STUD SIZE	DIMENSIONS												CABLE STRIP LENGTH	INSTALLATION TOOLING					
													DIELESS TOOLS			Y35, Y39, Y750, Y46					
	FLEXIBLE CABLE CODE AWG		B	C	C TOL.	E	K DIA.	L	N	P	T	Z MIN.	BELL	O.D.		MECHANICAL HYTOOL™(CRIMPS)	HYDRAULIC HYPRESS™	DIE INDEX	COLOR CODE	DIE NUMBER (# OF CRIMPS)	
"CONNECTORS BELOW ARE FOR FLEXIBLE CONDUCTOR ONLY"																					
YA382TC38FXB	535.3 Kcmil (1325/24)	3/8	3.08 [78]	1.84 [47]	±.06 [2]	1.00 [25]	.40 [10]	6.01 [153]	.50 [13]	3.89 [99]	.26 [7]	.53 [13]	1.47 [37]	1.25 [32]	3-3/16 [81]	---	Y644M (1 CRIMP)	L99	PINK	U38XRT (4 CRIMPS)	
YA382NFXB	535.3 Kcmil (1325/24)	1/2	3.08 [78]	1.84 [47]	±.06 [2]	1.75 [4]	.56 [14]	7.01 [178]	.62 [16]	3.89 [99]	.26 [7]	.64 [16]	1.47 [37]	1.25 [32]	3-3/16 [81]	---	Y644M (1 CRIMP)	L99	PINK	U38XRT (4 CRIMPS)	
YA382FXBG2	535.3 Kcmil (1325/24)	3/8	3.08 [78]	1.84 [47]	±.06 [2]	2.00 [51]	.40 [10]	6.82 [173]	.41 [10]	3.90 [99]	.27 [7]	.42 [11]	1.47 [37]	1.25 [32]	3-3/16 [81]	---	Y644M (1 CRIMP)	L99	PINK	U38XRT (4 CRIMPS)	
YA382FXBG3	535.3 Kcmil (1325/24)	1/2	3.08 [78]	1.84 [47]	±.06 [2]	1.19 [30]	.52 [13]	6.26 [159]	.53 [13]	3.90 [99]	.27 [7]	.55 [14]	1.47 [37]	1.25 [32]	3-3/16 [81]	---	Y644M (1 CRIMP)	L99	PINK	U38XRT (4 CRIMPS)	
----	----	----	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	
YA402NFXB	646 Kcmil (1600/24)	1/2	3.24 [82]	1.98 [50]	±.06 [2]	1.75 [44]	.56 [14]	7.22 [183]	.62 [16]	4.10 [104]	.30 [8]	.64 [16]	1.58 [40]	1.35 [34]	3-5/16 [84]	---	Y644M (1 CRIMP)	24	BLACK	U39RT (4 CRIMPS)	
----	----	----	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	
YA442TC38FXB	777.7 Kcmil (1925/24)	3/8	3.33 [85]	2.19 [56]	±.06 [2]	1.00 [25]	.40 [10]	6.44 [163]	.50 [13]	4.29 [109]	.33 [8]	.42 [11]	1.76 [45]	1.50 [38]	3-7/16 [87]	---	Y644M (1 CRIMP)	L115	YELLOW	U44XRT (4 CRIMPS)	
YA442TC58E16FXB	777.7 Kcmil (1925/24)	5/8	3.33 [85]	2.19 [56]	±.06 [2]	1.75 [44]	.68 [17]	7.44 [189]	.62 [16]	4.29 [109]	.33 [8]	.64 [16]	1.76 [45]	1.50 [38]	3-7/16 [87]	---	Y644M (1 CRIMP)	L115	YELLOW	U44XRT (4 CRIMPS)	
YA442NFXB	777.7 Kcmil (1925/24)	1/2	3.33 [85]	2.19 [56]	±.06 [2]	1.75 [44]	.56 [14]	7.44 [189]	.62 [16]	4.29 [109]	.33 [8]	.64 [16]	1.76 [45]	1.50 [38]	3-7/16 [87]	---	Y644M (1 CRIMP)	L115	YELLOW	U44XRT (4 CRIMPS)	
----	----	----	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	---	
YA462NFXB	1111 Kcmil (2750/24)	1/2	3.58 [91]	2.69 [68]	±.06 [2]	1.75 [44]	.56 [14]	7.91 [201]	.62 [16]	4.76 [121]	.39 [10]	.64 [16]	2.16 [55]	1.84 [47]	3-11/16 [94]	---	---	29	---	P45RT (4 CRIMPS)	
YA462NFXBUNPL	1111 Kcmil (2750/24)	1/2	3.58 [91]	2.69 [68]	±.06 [2]	1.75 [44]	.56 [14]	7.91 [201]	.62 [16]	4.76 [121]	.39 [10]	.64 [16]	2.16 [55]	1.84 [47]	3-11/16 [94]	---	---	29	---	P45RT (4 CRIMPS)	
YA462NFXBDTS	1111 Kcmil (2750/24)	1/2	3.58 [91]	2.69 [68]	±.06 [2]	1.75 [44]	.56 [14]	7.91 [201]	.62 [16]	4.76 [121]	.39 [10]	.64 [16]	2.16 [55]	1.84 [47]	3-11/16 [94]	---	---	29	---	P45RT (4 CRIMPS)	
YA482NFXB	1550 Kcmil, CLASS K	1/2	3.90 [99]	3.10 [79]	±.06 [2]	1.75 [44]	.56 [14]	8.42 [214]	.62 [16]	5.23 [133]	.46 [12]	.64 [16]	2.50 [64]	2.13 [54]	4-1/16 [103]	---	---	33	GRAY	L47RT Y60BH HYPRESS™ (2 CRIMPS)	
NOTES: 1. MATERIAL: COPPER 2. FINISH:TIN PLATED. FOR UNPLATED PARTS USE SUFFIX "UNPL" (EXAMPLE: YA26LTC12FXUNPL). FOR UNPLATED PARTS WITH INK MARKED BARREL USE SUFFIX "BR" (EXAMPLE: YAV6CLTC38FXBR). 3> CATALOG NUMBER "PUADP-1" ADAPTOR IS REQUIRED TO USE "U" TYPE DIES IN THE Y46 SERIES TOOLS. 4. REFERENCE THE BURNDY® PRODUCTS MASTER CATALOG "INSTALLATION TOOL INDEX" FOR ADDITIONAL TOOLING. 5. BELLED BARREL ENDS PROVIDE EASY CABLE INSERTION AND STRAIN RELIEF. 6. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY. 7> FOR UNDRILLED VERSIONS AND SUFFIX "U" TO END OF CATALOG NUMBER. FOR UNDRILLED VERSIONS,USE D MIN = N MAX + E MAX + Z MIN. 8> CONNECTORS ARE UL LISTED; UNDRILLED VERSIONS ARE NOT UL LISTED. 9> CONNECTORS ARE CSA CERTIFIED; UNDRILLED VERSIONS ARE NOT CSA CERTIFIED. 10> DTS SUFFIX STANDS FOR OIL SEAL TIGHT BRAZING.																					
TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES) FOR PRODUCT INFO: http://www.burndy.com																TELECOM BELLED HYLUG™					
																ITEM NO: N/A					
																CAT. NO: YA-2-FXB- (TABLE)					
																DRAWN BY: J. AYER		04/08/96			
																CHECKER: J. MICHAUD		04/09/96			
																DSN APPVL: C. PALAGI		01/24/96			
																MFG APPVL: --		--			
																QA APPVL: C.KOWALCZYK		11/07/2014			
																MKT APPVL: K.BOUTIN		11/05/2014			
																SCALE: NTS					
																PROD FAM: -		DRAWING NO		REV	
																PROJECT #: -		SIZE		J	
																DOCUMENT TYPE: Sales		D			
																REL LEVEL: Released		SHEET 5 OF 6			
REV		DATE		DESCRIPTION							ECO	BY	C.H.K.								
J		2017-10-06 00:00:00 EDT		ADD YA442NFC38FXB TO SALES DRAWING SE..208074-01.							47796	BM	MB								

