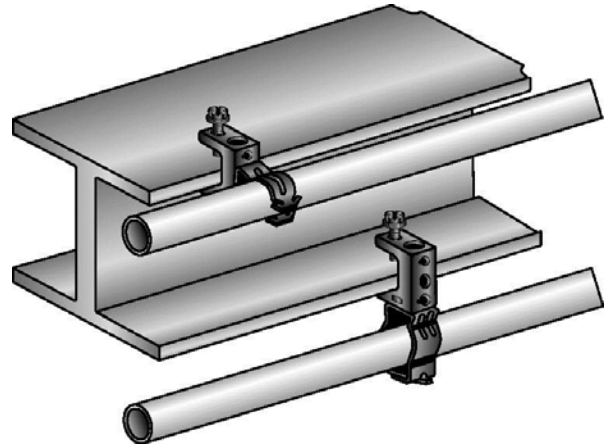
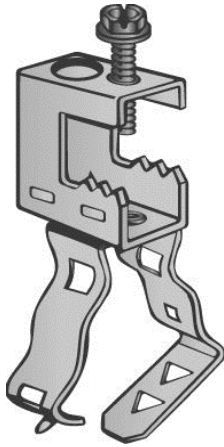


Part Number: PBC24M

Product Description: SCREW-ON BEAM CLAMP FOR UP TO 1/2" FLANGE WITH 1-1/2" CONDUIT CLIP

**Material Specifications**

Type: Assembly

Finish: Assembly

Color: Various

Function Specifications**Compatible Wires and Cables**

AC/MC CABLE (OD):

Drop Wire:

Plain Rod (in):

Threaded Rods and Bolts

Tapped Holes: 1/4-20 & #10-24

Clearance Holes (in): 1/4

Threaded Rod Size (in):

Compatible Conduit

EMT Size (in): 1-1/2

Rigid/IMC (in): 1-1/2

Compatible Flanges and Studs

Flange Size (in): Up to 1/2

Metal Stud Size (ins):

Static Load Rating

Vertical (lbs): 100

Horizontal (lbs): 25

Other

1/4-20 (back) #10-24 (back)

Codes and RegulatoryRegulatory
Certifications:

-

Country of Origin: US

--

Packaging

General Packaging: Cardboard Box

Box Size: 15 X 8.25 X 7.25

Pieces per Package: 100

Other Box Features:

Document Information

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11116

Revision Level: 01

ECN #: GAECN01482

Date: 12/10/2013
