


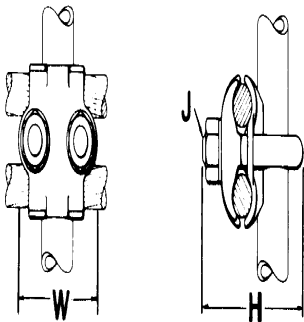

BURNDY Catalog Number
UPC Number
Description
Status

GP1426
 7818102605866
 4SOL-2/0STR, 1 IPS, 2 CO
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in)	2.38
Height (in)	3.00
Size (Hex) or Size (Bolt)	3/8
Size (Hex) or Size (Bolt) - in	0.38
Width (Fraction)	2-3/8
Height (Fraction) (in)	3

General

Product Description	Mechanical Grounding Connector, 2 Cables to Rod or Pipe, 4 AWG (Sol.) - 2/0 AWG (Str.), 1/2" - 3/4" Pipe, 7/8" - 1" Rod, 3/8" Stud
---------------------	---

Conductor(s)

Copper Tube Size (SCH40) - Range	1
Rod Size (Range)	7/8 in-1 in
Copper Solid Size (Range)	4-3/0
Copper Stranded (Range)	5-2/0

Physical

Installation Torque	240
Type of Plating	Unplated
Plated (Yes or No)	N
Product Material	Copper Alloy

Approvals / Certifications

UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
UL Recognized	N
CULUS	N
Industry Standards	UL467
Rated for Direct Burial	Y

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175