



BURNDY Catalog Number
UPC Number

YS34A1
7818107575500
ALUMINUM BUTT SPLICE, 5.02 IN
L
Active


Description
Status

Web Use
BURNDY Product Line

Strip Length
Barrell Style
Barrel Type

Dimensional
2-5/8
Chamfered
Standard

General
Aluminum Compression Splice,
500 kcmil, 5" Splice Length, Long
Barrel, Tin Plated

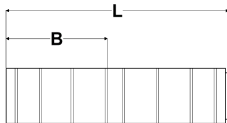

Product Description

Conductor(s)
500 kcmil
500 kcmil

Aluminum Size (Range)
Copper Stranded (Range)

Physical
300

Index Number

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175