




**BURNDY Catalog Number**  
**UPC Number**

TN1014  
 7818107342099  
 RING- 12- 10 AWG-NYLON, 1.32  
 IN L  
 Active

**Description**  
**Status**

**Web Use**  
 BURNDY Product Line

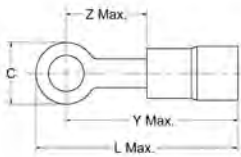

**Dimensional**

Max Insulation Diameter 0.21  
 Length (in) 1.32  
 Tongue Type Ring  
 Pad Width (in) 0.53  
 Strip Length 11/32

**Electrical**

Max Voltage Rating 600

**General**

Product Description Copper Terminal, Ring Tongue,  
 12-10 AWG, #12, 1/4" Stud, 600  
 Volts Max., Nylon Insulated,  
 Funnel Entry, Tin Plated

**Other**

Bulk Package YAES10N57

**Physical**

Type of Plating Tin - Electro Plated  
 Connector Type Terminal  
 Color Code Yellow  
 Insulation Type Nylon  
 Plated (Yes or No) Y

**Approvals / Certifications**

UL Listed Y  
 CSA Certified Y  
 ROHS Compatible Compliant  
 UL Recognized N  
 CULUS N  
 Industry Standards UL486

**Conductor(s)**

Copper Solid Size (Range) 12 AWG-10 AWG  
 Copper Stranded (Range) 12 AWG-10 AWG

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175