


 


BURNDY Catalog Number
UPC Number

TP168F
7818107146833
FORK- 22- 16 AWG- VINYL, 0.86
IN L
Active

Description
Status

Web Use
BURNDY Product Line

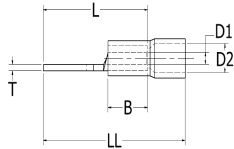

Dimensional

Max Insulation Diameter 0.145
Length (in) 0.86
Tongue Type Fork
Pad Width (in) 0.31
Strip Length 13/64

Electrical

Max Voltage Rating 600

General

Product Description Copper Terminal, Fork Tongue, 22-16 AWG, #6-#8 Stud, Vinyl Insulated, Tin Plated

Other

Bulk Package BA16EF8M

Physical

Type of Plating Tin
Connector Type Terminal - Fork
Color Code Red
Insulation Type Vinyl
Plated (Yes or No) Y

Approvals / Certifications

UL Listed Y
CSA Certified Y
ROHS Compatible Compliant
UL Recognized N
CULUS N

Conductor(s)

Copper Solid Size (Range) N/A
Copper Stranded (Range) 20 AWG-16 AWG

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175