




BURNDY Catalog Number
UPC Number
Description
Status

YS27LBOX
7818105565044
3/0 STR. CU. BUTT SPLICE
Active

Web Use
BURNDY Product Line

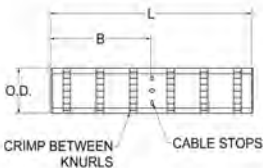

Dimensional	
Strip Length	1-1/16
Barrell Style	Chamfered
Barrel Type	Standard
General	
Product Description	Copper Compression Splice, 3/0 AWG, 2.30" Splice Length, Short Barrel, Tin Plated
Physical	
Type of Plating	Tin - Electro Plated
Plated (Yes or No)	Y
Index Number	14,101
Product Material	Copper
Approvals / Certifications	
UL Listed	Y
CSA Certified	Y
ROHS Compatible	Compliant
UL Recognized	N
CULUS	N
Industry Standards	UL468A-468B
Documentation	

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175