


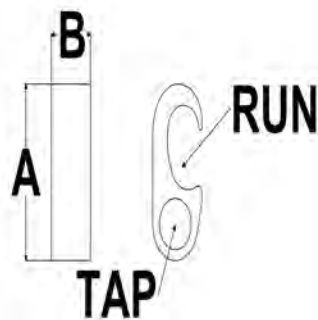

BURNDY Catalog Number
UPC Number
Description
Status

YGHP29C29
 7818102209488
 1/0-250 TO 3/0-250 GRN C
 Active

Web Use
 BURNDY Product Line

Dimensional	
B Length (in)	0.75
B Length (Fraction)	3/4
General	
Product Description	Cu Compression Ground Rod Connector, 3/0 Str - 250 Kcmil, 1/2" - 5/8" Rod Dia
Prefilled (Oxide Inhibitor)	Y
Other	
Type of Oxide Inhibitor	Penetrox E
Approvals / Certifications	
Rated for Direct Burial	Y
UL Listed	Y
CSA Certified	Y
ROHS Compatible	Compliant
UL Recognized	N
CULUS	N
Industry Standards	UL467, IEEE 837
Conductor(s)	
Copper Tap Range	3/0 AWG-250 kcmil
Copper Stranded Run (Range)	1/0 -250 kcmil
Copper Solid Tap (Range)	N/A
Copper Solid Run Size (Range)	N/A
Physical	
Type of Plating	Unplated
Connector Type	Tap
Plated (Yes or No)	N
Index Number	997
Product Material	Copper
Documentation	

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175