

BURNDY Catalog Number
UPC Number
Description
Status

YC28C26
7818101160055
3/0-4/0 TO 1/0-2/0 CU FI
Active

Web Use
BURNDY Product Line

Length (Fraction)

Dimensional
1-1/6

General

Product Description

CU Compression C Shape
Compression Connector, 600 Volts
to 35 Kv, Run: 3/0 Str. - 4/0 Str.,
Tap: 1/0 Str. - 2/0 Str.

Conductor(s)

Copper Tap Range
Copper Stranded Run (Range)
Copper Solid Tap (Range)
Copper Solid Run Size (Range)

1/0 AWG-2/0 AWG
3/0 AWG-4/0 AWG
1/0 AWG-2/0 AWG
3/0 AWG-4/0 AWG

Physical

Type of Plating
Plated (Yes or No)
Product Material


Unplated
N
Copper

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Y
Y
Compliant
N
N
UL 486A,UL486B

Documentation

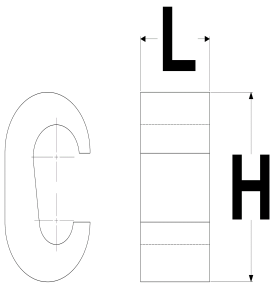

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175