




On Line Catalog



BURNDY Catalog Number
UPC Number
Description
Status

YAZV2C2TC14E2FX
7818102282966
CULUG- 2 FLEX-LONG W/PORT-
1/4STUD, 2HOLE
Active

Web Use
BURNDY Product Line

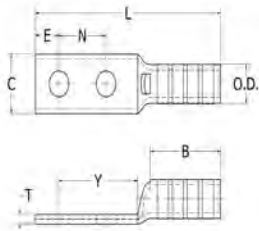

Tongue Angle
Strip Length
Length (in)
Height (in)
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in

Dimensional

Straight
1-7/16
3.13
0.46
Skived
0.27
Long
0.10
1.38
0.68
0.75

Number of Holes

General

2
Cu compression long barrel flex
conductor, 2 holes/W/ insp
window, #2 weld(125/24-150/24),
#2AWG, 1/4" stud, Tin plated,
Brown

Product Description

Conductor(s)

Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

N/A
N/A
2 AWG

Physical

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Tin
1/4
Brown
Y
10
Copper

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

BURNDY Technical Services

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175

5/30/2018

Datasheet - Burndy - YAZV2C2TC14E2FX

47 East Industrial Park Drive
Manchester NH 03109

47 East Industrial Park Drive
Manchester NH 03109