




BURNDY Catalog Number
UPC Number
Description
Status

GAR3902
7818102340133
4-4/0, 1/2-1 IPS
Active

Web Use
BURNDY Product Line

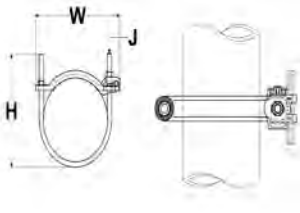

Dimensional

Width (in) 3.25
Length (in) 1.75
Height (in) 3.50
Size (Hex) or Size (Bolt) 3/8
Size (Hex) or Size (Bolt) - in 0.38
B Length (in) 1.75

General

Product Description

Mechanical Grounding Connector,
Conductor to Water Pipe, 4-4/0
AWG, 1/2"-1" Pipe, 3/8" Stud

Other

Type of U Bolt

1031G

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards
Rated for Direct Burial

Y
Y
Compliant
N
N
UL467
Y

Conductor(s)

Copper Tube Size (SCH40) - Range 1/2-1
Rod Size (Range) N/A
Copper Solid Size (Range) N/A
Copper Stranded (Range) 4-4/0
Rebar Size (Range) N/A

Physical

Type of Hardware
Installation Torque
Type of Plating
Plated (Yes or No)
Product Material

Steel - Galvanized
200
Unplated
N
Copper Alloy

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175