




**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GAR3903  
 7818102340200  
 4-4/0, 1-1/4 TO 2 IPS  
 Active

**Web Use**  
 BURNDY Product Line

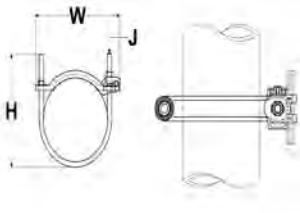

Width (in)  
 Length (in)  
 Height (in)  
 Size (Hex) or Size (Bolt)  
 Size (Hex) or Size (Bolt) - in  
 B Length (in)

#### Dimensional

4.25  
 1.75  
 4.00  
 3/8  
 0.38  
 1.75

Product Description

#### General

Mechanical Grounding Connector,  
 Conductor to Water Pipe, 4-4/0  
 AWG, 1-1/4" - 2" Pipe, 3/8" Stud

Type of U Bolt

#### Other

1032G

#### Approvals / Certifications

UL Listed  
 CSA Certified  
 ROHS Compatible  
 UL Recognized  
 CULUS  
 Industry Standards  
 Rated for Direct Burial

Y  
 Y  
 Compliant  
 N  
 N  
 UL467  
 Y

#### Conductor(s)

Copper Tube Size (SCH40) - Range  
 Rod Size (Range)  
 Copper Solid Size (Range)  
 Copper Stranded (Range)  
 Rebar Size (Range)

1 1/4-2  
 N/A  
 N/A  
 4-4/0  
 N/A

#### Physical

Type of Hardware  
 Installation Torque  
 Type of Plating  
 Plated (Yes or No)  
 Product Material

Steel - Galvanized  
 200  
 Unplated  
 N  
 Copper Alloy

#### Documentation

**For further technical assistance, please contact us**

#### BURNDY LLC - USA

47 East Industrial Park Drive  
 Manchester NH 03109

#### BURNDY Technical Services

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175