




BURNDY Catalog Number
UPC Number
Description
Status

GAR3909
 7818102340822
 4-4/0, 12 IPS
 Active

Web Use
 BURNDY Product Line

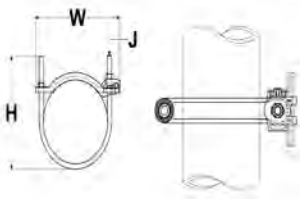

Width (in)
 Length (in)
 Height (in)
 Size (Hex) or Size (Bolt)
 Size (Hex) or Size (Bolt) - in
 B Length (in)

Dimensional
 14.75
 1.75
 14.00
 3/8
 0.38
 1.75

Product Description

General
 Mechanical Grounding Connector,
 Conductor to Water Pipe, 4-4/0
 AWG, 12" Pipe, 3/8" Stud

Type of U Bolt

Other
 1030G

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards
 Rated for Direct Burial

Approvals / Certifications
 Y
 Y
 Compliant
 N
 N
 UL467
 Y

Copper Tube Size (SCH40) - Range
 Rod Size (Range)
 Copper Solid Size (Range)
 Copper Stranded (Range)
 Rebar Size (Range)

Conductor(s)
 12
 N/A
 N/A
 4-4/0
 N/A

Type of Hardware
 Installation Torque
 Type of Plating
 Plated (Yes or No)
 Product Material

Physical
 Steel - Galvanized
 200
 Unplated
 N
 Copper Alloy

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175