



BURNDY Catalog Number
UPC Number
Description
Status

YS30L
7818105081522
300 MCM CU. BUTT SPLICE
Active

Web Use
BURNDY Product Line

Dimensional

Strip Length 1-1/8
Barrell Style Chamfered
Barrel Type Standard

General

Product Description Cu Comp Butt Splice(Code), 300
Navy, 300 kcmil(Com'l Cable), 600
V-35 kV, 2.47" L, Std bbl, Tin
Plated, White


Physical

Type of Plating Tin - Electro Plated
Plated (Yes or No) Y
Index Number 17,298
Product Material Copper

Approvals / Certifications

UL Listed Y
CSA Certified Y
ROHS Compatible Compliant
UL Recognized N
CULUS N
Industry Standards UL468A-468B

Documentation

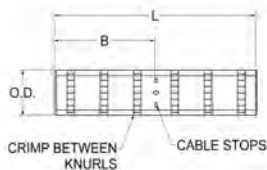

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
Monday - Friday
Phone: 800-346-4175