




# Thin Client

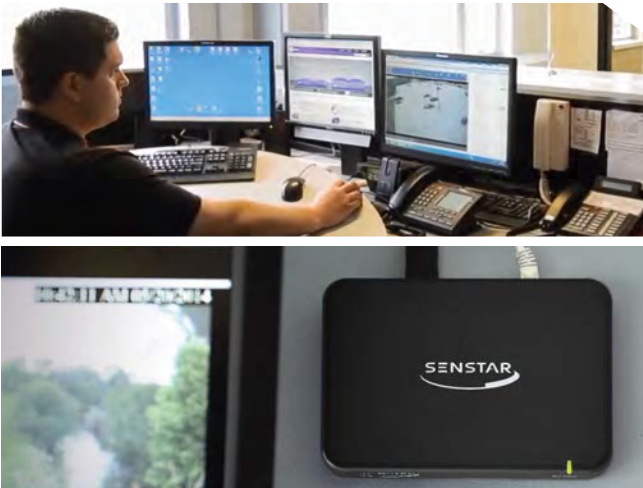

## Industry Disruptive PC Alternative for Displaying and Reviewing Security Video

The Thin Client is an open, simple, and cost-effective PC alternative designed to easily display 1080p video from 30+ network video manufacturers.

The Thin Client is perfect for the dual purpose of displaying IP surveillance video and digital signage. The device is ideal in space constrained environments such as hospitals, banking, and retail, due to its easy setup and compact design.

## Key Benefits

### Open

The Thin Client supports over 30 network camera manufacturers, so it can easily be integrated into existing security deployments and new projects.

### Flexible

Installation takes less than five minutes with the capability to connect to iPhone & Android apps for remote control of cameras and multiple screen layouts.

### Easy Video Playback and Export

The Thin Client pairs perfectly with the Symphony™ VMS for easy surveillance video playback and export. This functionality of the Thin Client is ideal when you need a quick and low cost way to review and export surveillance footage for internal use or for review by authorities without sacrificing quality.

### Lower Total Cost of Ownership

The Thin Client delivers the performance you need at a fraction of the cost. As a fanless, PoE powered product, the device draws 95 percent less energy than a Windows® PC. Secure and simplified IT management reduces end user training that significantly reduces short and long term costs.

# Features and Specifications

## Hardware Specifications

OS	Linux
Video Output	1 x HDMI (1080p)
Supported Views	Smart 2-View Split-Screen Display
	1: 1920 x 1080 @ 30 fps   9: 640x 360 @ 20 fps
	4: 960 x 540 @ 25 fps   12: 480 x 270 @ 10 fps
	6: 640 x 450 @ 20 fps   16: 480 x 270 @ 10 fps
Video Compression	H.264, MPEG-4, Motion JPEG
USB 2.0 Port	2
Ethernet	1 x Gigabit
Security	Password Protection
Network Protocols	TCP, UDP, IP, HTTP, RTSP, ICMP, ARP, DHCP, DNS
Operating Temp.	0 - 45°C
Storage Temp.	- 20 - 45°C
Dimensions (mm)	175W x 120D x 35H
Weight	600 g
Power	PoE IEEE 802.3af Class 3, max. 8.5 W
Compliance	CE, FCC, RoHs
Mounting Kit	Wall, VESA (sold separately)
Included Accessories	1 HDMI cable, Installation Guide
Warranty	2 year

## Rear Ports



## Key Features

- Decode high definition, 1080p video from 30+ network video manufacturers
- Live, playback, and video export ability when connected to Symphony
- Stream digital signage using a USB flash drive
- VESA, wall, or desktop mount options
- PoE powered for less energy use
- Centralize firmware management and health monitoring with Enterprise Manager™ integration

## Control Options

Mouse control



Touch screen

HDMI-CEC

Web

iPhone, iPad

Android

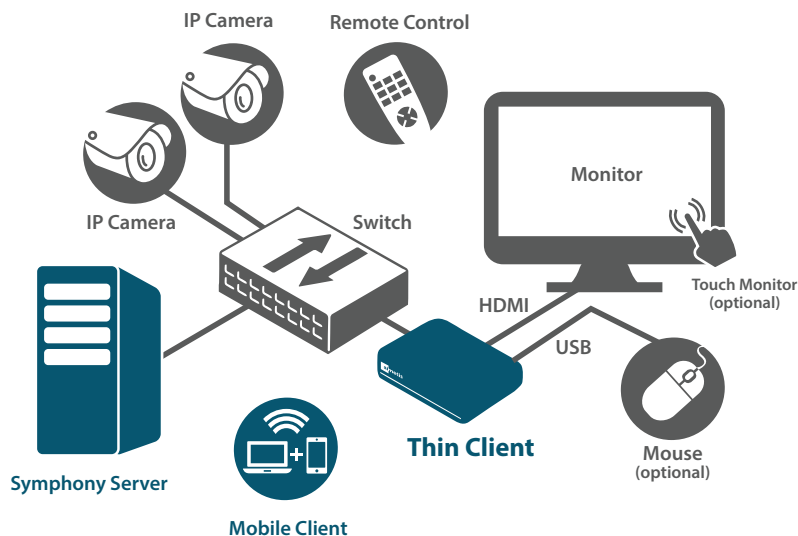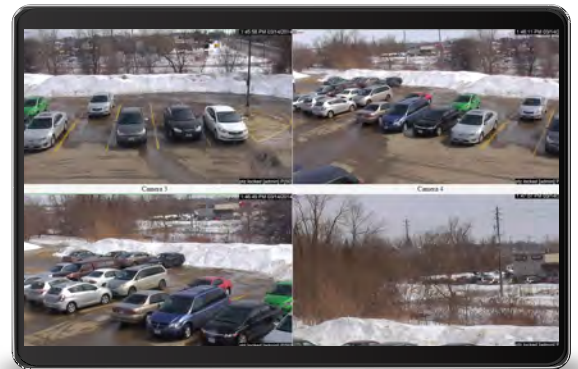

[info@senstar.com](mailto:info@senstar.com) • [senstar.com](http://senstar.com)

Copyright © 2018. All rights reserved. Features and specifications are subject to change without notice. The Senstar name and logo are registered trademarks of Senstar Corporation. Symphony and Enterprise Manager are trademarks of Senstar Corporation. All other trademarks and trade names are the property of their respective holders. Version: 01/25

