

Model B®

Spring Roller-Type Screen



SPECIFICATION DATA

SUGGESTED SPECIFICATIONS: _____ projection screen(s),
 _____(H) x _____(W), wall or ceiling mounting type. Screen to have
 a powder coated white 22-gauge octagonal steel case with flat back design
 and fitted with end caps concealing roller ends with integral bearing surface
 to support roller and integral brackets for wall mounting by means of slotted
 screw holes and ceiling mounting by means of powder coated hanger rings.
 Bottom of fabric shall be mounted securely into a powder coated tubular

steel slat. Ends of slat shall be protected by plastic caps. A steel pull bail shall
 be attached to slat. A 36" (91 cm) pull cord with plastic knob is included. To
 have masking borders standard on flame retardant and mildew resistant
 fiberglass fabric. Fabric shall be mounted into a metal strip in a metal Camlok®
 roller system without tape, glue, staples or cords so that fabric may be easily
 replaced yet cannot be pulled from roller.

HDTV (16:9) Format Dimensions

Viewing Area (H x W)		Nominal Diagonal		A - Overall Length of Case		B - Between Hanger Eyes		C - Brackets		D - Case Diameter (Width)		Approx. Ship. Wt.	
In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	Lbs.	Kg
37½" x 67"	95 x 170	77"	196	73¾"	186	72¾"	184	3¾"	8.6	2½"	6	15	6.8
45" x 80"	114 x 203	92"	234	87¾"	222	86¾"	220	3¾"	9.2	2¾"	7	23	10.4
52" x 92"	132 x 234	106"	269	99¾"	252	98¾"	251	3¾"	9.2	2¾"	7	26	11.8

(16:10) Wide Format Dimensions

Viewing Area (H x W)		Nominal Diagonal		A - Overall Length of Case		B - Between Hanger Eyes		C - Brackets		D - Case Diameter (Width)		Approx. Ship. Wt.	
In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	Lbs.	Kg
50" x 80"	127 x 203	94"	239	87¾"	222	86¾"	220	3¾"	9.2	2¾"	7	24	10.9
57½" x 92"	146 x 234	109"	277	99¾"	252	98¾"	251	3¾"	9.2	2¾"	7	27	12.3

Video (NTSC 4:3) Format Dimensions

Viewing Area (H x W)		Nominal Diagonal		A - Overall Length of Case		B - Between Hanger Eyes		C - Brackets		D - Case Diameter (Width)		Approx. Ship. Wt.	
In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	Lbs.	Kg
43" x 57"	109 x 145	72"	183	63¾"	161	62¾"	159	3¾"	8.6	2½"	6	13	5.9
50" x 67"	127 x 170	84"	213	73¾"	186	72¾"	184	3¾"	8.6	2½"	6	15	6.8
60" x 80"	152 x 203	100"	254	87¾"	222	86¾"	220	3¾"	9.2	2¾"	7	24	10.9
69" x 92"	175 x 234	120"	305	99¾"	252	98¾"	251	3¾"	9.2	2¾"	7	27	12.3


Square Format Dimensions

Sizes (H x W)		A - Overall Length of Case		B - Between Hanger Eyes		C - Brackets		D - Case Diameter (Width)		Approx. Ship. Wt.	
In.	Cm	In.	Cm	In.	Cm	In.	Cm	In.	Cm	Lbs.	Kg
40" x 40"	102 x 102	43¾"	110	42¾"	108	3¾"	8.6	2½"	6	9	4.1
50" x 50"	127 x 127	53¾"	136	52¾"	134	3¾"	8.6	2½"	6	12	5.4
60" x 60"	152 x 152	63¾"	161	62¾"	159	3¾"	8.6	2½"	6	14	6.4
70" x 70"	178 x 178	73¾"	186	72¾"	184	3¾"	8.6	2½"	6	17	7.7
72" x 72"	183 x 183	75¾"	191	74¾"	190	3¾"	9.2	2¾"	7	19	8.6
84" x 84"	213 x 213	87¾"	222	86¾"	220	3¾"	9.2	2¾"	7	26	11.8
96" x 96"	244 x 244	99¾"	252	98¾"	251	3¾"	9.2	2¾"	7	30	13.6

PRODUCT NOTES

- **Matte White, Video Spectra 1.5 and High Contrast Matte White:** Surfaces will be seamless in standard sizes.
- Overall case length dimensions +/- ¼" (6 mm).
- Specifications subject to change without notice.
- Hanger rings add ¾" (19 mm) to the overall dimension C.
- Custom formats and sizes available upon request.
- **Optional Accessories:** to provide clearance: Furnish 6" (15 cm) heavy extension wall brackets to mount screen. To provide for keystone elimination: Furnish #11 or #23 adjustable extension wall brackets. Furnish magnetic tilt lock for keystone elimination.
- **NOTE:** Brackets also are used for mounting screen across a corner.

PRODUCT VIEWS

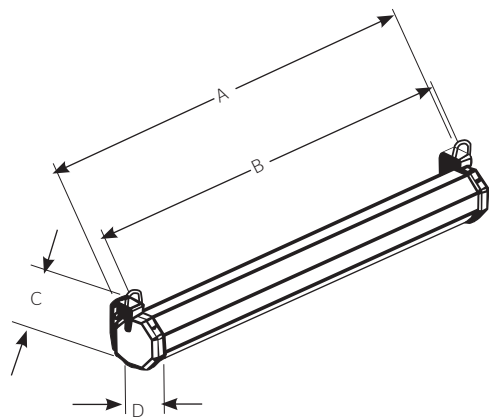

A BRAND OF MILESTONE AV TECHNOLOGIES
www.milestone.com
P 800.622.3737 / 574.267.8101
F 877.325.4832 / 574.267.7804
E info@da-lite.com


In British Columbia, Milestone AV Technologies ULC carries on business as MAVT Milestone AV Technologies ULC.

©2017 Milestone AV Technologies. DL-0224 (Rev. 1) 0617.
Da-Lite is a registered trademarks of Milestone AV Technologies. All other brand names or marks are used for identification purposes and are trademarks of their respective owners. All patents are protected under existing designations. Other patents pending.

WHEN ORDERING, MARK APPROPRIATE SELECTIONS:

1. Select size from charts on the other side.
2. Select viewing surface (All Da-Lite surfaces are GREENGUARD GOLD Certified):
 - ☐ Matte White
 - ☐ Video Spectra 1.5
 - ☐ High Contrast Matte White
3. Optional accessories:
 - ☐ No. 6 Wall Bracket - 6" (15 cm) non-adjustable extension brackets (140#, 63.5 kg, per pair maximum) (black or white).
 - ☐ Tilt-Lock for Keystone Elimination (used with extension brackets).
 - ☐ No. 11 Wall Bracket - 10" or 14" (25 or 36 cm) non-adjustable extension brackets (75#, 34 kg, per pair maximum) (black or white).
 - ☐ T-Bar Clip for drop ceilings (50#, 23.7 kg, per pair maximum) (black or white).
 - ☐ No. 23 Adjustable Wall Bracket - 10", 14", 15¾", 18¾", 20" or 24" (25, 36, 40, 46, 51 or 61 cm) adjustable extension brackets (75#, 34 kg, per pair maximum) (black or white).
 - ☐ Pull Rod - 38" (97 cm).
 - ☐ No borders (Black masking borders standard).
 - ☐ Black case (white standard).


ACCESSORIES

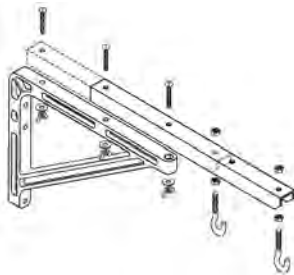

No. 23 Adjustable Wall Bracket
Screen can be extended 10", 14", 15¾", 18¾", 20" or 24" from wall by wing nut and bolt adjustment.




No. 11 Wall Bracket
Screen can be extended 10" or 14" from wall by changing position of bracket.

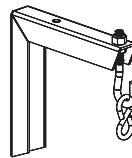


No. 6 Wall Bracket
Screen can be extended 6" from wall.


Extension Wall Brackets

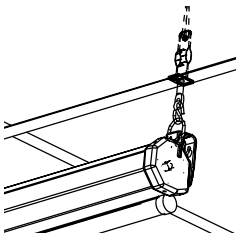

T-Bar Clip for drop ceiling, 50 lb. capacity.

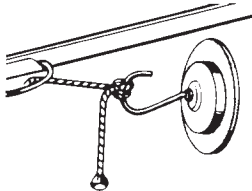

Tilt Lock for Keystone elimination. Used with extension brackets.

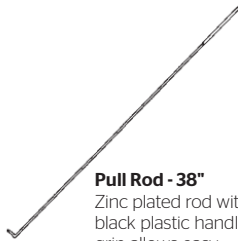

Pull Rod - 38"
Zinc plated rod with black plastic handle grip allows easy access to screen when mounted out of reach. Also can be used as a pointer.

Project Name: _____

Architect: _____

Contractor: _____ Phone: _____

Reseller: _____ Phone: _____