



DON'T JUST INSTALL, THINSTALL™

Chief's Thinstall Series Swing Arm Mounts are ultra low-profile full-motion wall mounts for LED, LCD and plasma TVs and displays. These sleek, ruggedly-constructed solutions have low 1.5 to 1.8" (38 to 46 mm) profiles, are easy to install and extend up to 25" (635 mm).

FEATURES

- 1 FULL EXTENSION**
Arms extend out up to 25" (635 mm) for maximum viewing potential.
- 2 ULTRA LOW-PROFILE**
These sleek designs collapse 1.5 to 1.8" (38 to 46 mm) providing an ultra-thin profile.
- 3 CONTROLZONE™ HEIGHT ADJUSTMENT**
Adjust the height of your entire configuration post-installation up to 1" (25 mm).
- 4 CENTERLESS™ LATERAL SHIFT**
Get up to 16" (406 mm) of post-installation shift for limitless centering possibilities.
- 5 CENTRIS™ LOW-PROFILE FINGERTIP TILT**
Provides up to 15° of fingertip tilt to achieve the perfect viewing angle.
- 6 INTEGRATED CABLE MANAGEMENT**
Enclosed, tool-less cable covers and a wide open wall plate make it easy to route power and signal cables.





TS525TU

for 37 - 58" displays

TS325TU

for 26 - 52" displays

TS318TU

for 26 - 52" displays



TS218SU

for 26 - 47" displays

TS118SU

for 10 - 32" displays

TS110SU

for 10 - 32" displays

SWING ARM SPECIFICATIONS

Model	TV Size Range	Depth	Extension	Centerless Lateral Shift	Centris Low-Profile Tilt	Max Mounting Pattern (WxH)	Weight Capacity
TS525TU	37 - 58"	1.5" (38 mm)	25" (635 mm)	16" (406 mm)	-15°	800 x 400 mm	125 lbs (56.7 kg)
TS325TU	26 - 52"	1.8" (46 mm)	25" (635 mm)	16" (406 mm)	-15°	600 x 400 mm	75 lbs (34 kg)
TS318TU	26 - 52"	1.8" (46 mm)	18" (457 mm)	16" (406 mm)	-15°	600 x 400 mm	75 lbs (34 kg)
TS318SU	26 - 52"	1.8" (46 mm)	18" (457 mm)	0" (single stud)	-15°	600 x 400 mm	75 lbs (34 kg)
TS218SU	26 - 47"	1.5" (38 mm)	18" (457 mm)	0" (single stud)	-12°	400 x 400 mm	75 lbs (34 kg)
TS118SU	10 - 32"	1.5" (38 mm)	18" (457 mm)	0" (single stud)	-12°	200 x 200 mm	35 lbs (15.9 kg)
TS110SU	10 - 32"	1.5" (38 mm)	10" (254 mm)	0" (single stud)	-12°	200 x 200 mm	35 lbs (15.9 kg)

THININSTALL SWING ARM ACCESSORIES

TA100/TA110 Component Shelf

- TA100 compatible with TS500 and TS300 series, TA110 compatible with TS200 and TS100 series
- Height adjustable shelf sits above or below TV to accommodate different component and screen sizes
- Adds 0.13" (3 mm) of depth to installation



TA500 In-Wall Accessory Box

- Allows a TS525TU or TS325TU to be recessed into a standard depth wall for a zero-profile installation
- Allows height and lateral adjustment of screen
- Requires a 34.25 x 22" (870 x 559 mm) opening in a standard depth wall



TA200/TA250 Camera Shelves

- 8" or 12" (203 mm or 305 mm) wide shelf
- Compatible with TS500 and TS300 series swing arms
- Height adjustable shelf sits above or below TV to accommodate different camera and screen sizes
- Adds 0.13" (3 mm) of depth to installation



TA501 In-Wall Accessory Box

- Allows a TS318U to be recessed into a standard wall for a zero-profile installation
- Allows height and lateral adjustment of screen
- Installs on a standard 16" on center stud wall (requires 1 stud to be cut and reinforced)
- Requires a 30.25 x 24" (768 x 610 mm) opening in a standard depth wall



TA300 Left/Right Speaker Adapter

- Compatible with TS500 and TS300 series swing arms
- Infinitely adjustable to fit speakers flush with sides of TV
- Adds 0.13" (3 mm) of depth to installation



TA502 In-Wall Accessory Box

- Allows a TS218SU or TS118SU to be recessed into a standard wall for a zero-profile installation. Installs in between standard 16" on center studs
- Requires a 14.5 x 14.5" (368 x 368 mm) opening in a standard depth wall
- For TVs with mounting patterns larger than 200 x 200 mm, depth from wall will be 0.38" (9 mm)



TA350 Center Channel Speaker Adapter


- Compatible with TS500 and TS300 series swing arms
- Infinitely adjustable to fit speaker flush with top or bottom of TV
- Adds 0.13" (3 mm) of depth to installation



TA410 Portrait Adapter


- Compatible with TS500 and TS300 series swing arms
- Allows displays to be installed in portrait orientation
- Not necessary for TVs having VESA 200 x 200 or 100 x 100 mounting patterns
- Adds 0.13" (3 mm) of depth to installation



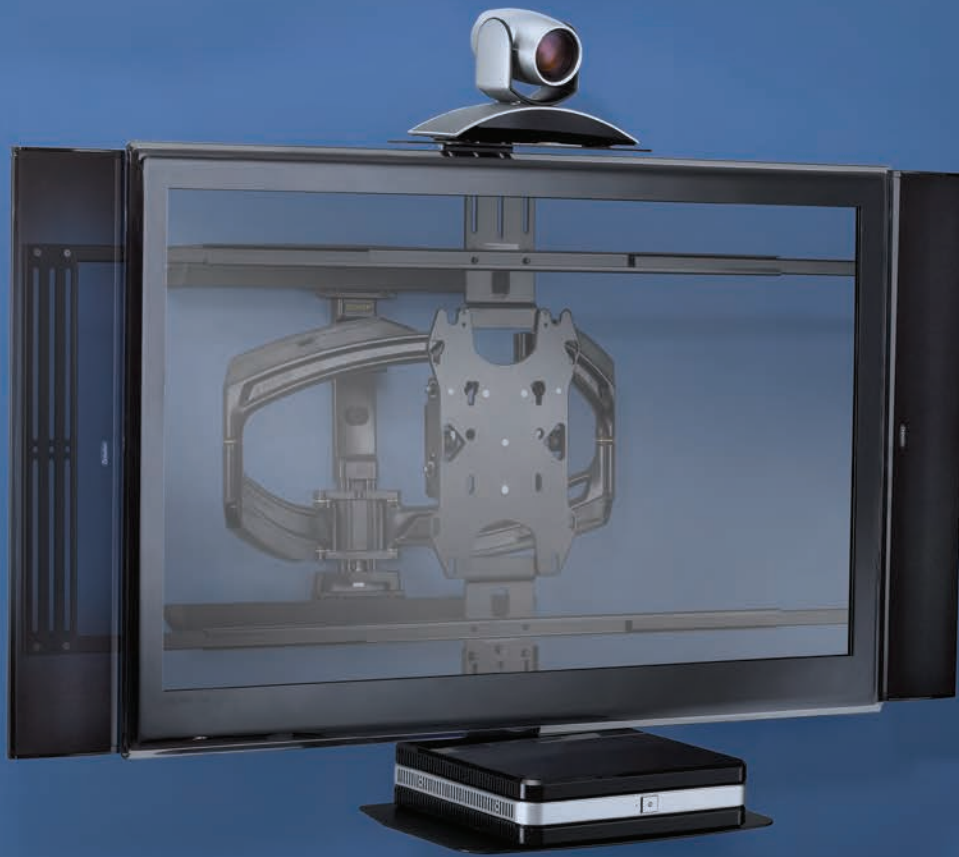

VIDEO CONFERENCING

HOME THEATER

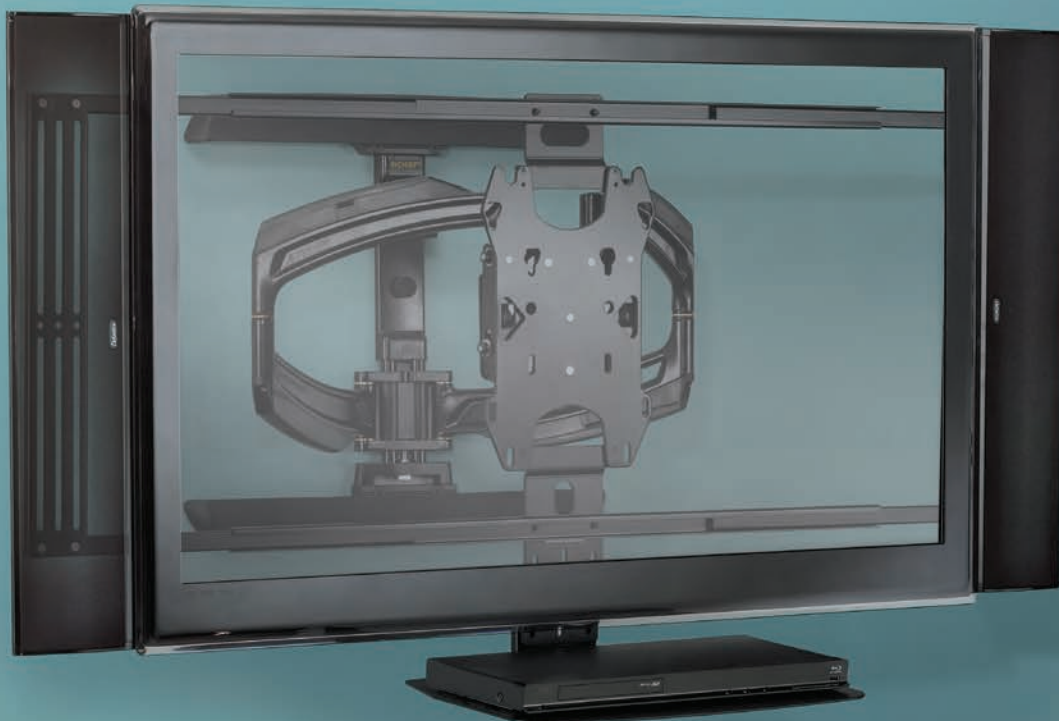

THININSTALL™ FIXED & TILT MOUNT FEATURES

GLIDE LOCK™ LATCHING SYSTEM

Tool-less latching for faster installation

EASY CABLE ACCESS

Unique kickstand allows easy cable access when needed

HOOK & LOOP STRAPS

Retract the cable kickstand by simply pulling the straps

IN-WALL BOX

Optional storage box for a clean installation



LTTU Tilt Mount
for 37 - 63" displays

MTTU Tilt Mount
for 26 - 47" displays

LSTU Fixed Mount
for 37 - 63" displays

MSTU Fixed Mount
for 26 - 47" displays

FIXED & TILT MOUNT SPECIFICATIONS

Model	TV Size Range	Depth	Mounting Pattern (WxH)	Max Screen Thickness	Tilt	Weight Capacity
LTTU*	37 - 63"	0.75" (19 mm)	200 x 200 mm to 800 x 500 mm	2.0" (51 mm)	12°	100 lbs (45.4 kg)
MTTU*	26 - 47"	0.75" (19 mm)	100 x 100 mm to 600 x 400 mm	2.0" (51 mm)	12°	100 lbs (45.4 kg)
LSTU	37 - 63"	0.39" (10 mm)	200 x 200 mm to 800 x 500 mm	5.0" (127 mm)	--	125 lbs (56.7 kg)
MSTU	26 - 47"	0.39" (10 mm)	100 x 100 mm to 600 x 400 mm	5.0" (127 mm)	--	125 lbs (56.7 kg)

*Can only be used with TVs or displays 2" (50.8 mm) deep or less.



IN-WALL SOLUTIONS

Chief's in-wall storage solutions come loaded with features and ordering options to provide installers what they need, when they need it.

- Break away edges change the depth of the box in order to match either 3.5" or 2.5" studs (89 or 64 mm)*
- Separate ordering for box, flange and cover to match when pieces are actually needed in the field, and at no additional MSRP or list pricing cost
- Large enough space to hold commonly used video scalars and other AV or ITE equipment per UL2416 and UL2442 listings
- Integrated universal zip tie anchor points
- Breakaway knockouts in the cover for cable routing and ventilation as well as tamper proof security
- Drywall and stud mountable
- Black or white flanges and covers, paintable to blend with any environment
- Packaging that also serves as a wall template and temporary cover

**Non-powered boxes only.*



PAC525F

9 x 14.25" In-Wall
Box w/ Flange



PAC526FC

14.25 x 14.25" In-Wall Box
w/ Flange & Cover



PAC526FP4

14.25 x 14.25" In-Wall Box w/
Flange & 4 Power Receptacles

FEATURES



Breakaway Edge



Drywall Cleat



Knockout

PAC525 ORDERING OPTIONS



Dimensions
 9 x 14.25 x 3.9"
 (229 x 362 x 99 mm)

Model	In-Wall Box	Black Flange	Black Cover	White Flange	White Cover	Power Receptacles
PAC525	x					
PAC525F	x	x				
PAC525FBP2	x	x				2
PAC525FW	x			x		
PAC525FWP2	x			x		2
PAC525FC	x	x	x			
PAC525FCW	x			x	x	
PAC525F-KIT		x				
PAC525FW-KIT				x		
PAC525CVR-KIT			x			
PAC525CVRW-KIT					x	

PAC526 ORDERING OPTIONS



Dimensions
 14.25 x 14.25 x 3.9"
 (362 x 362 x 99 mm)

Model	In-Wall Box	Black Flange	Black Cover	White Flange	White Cover	Power Receptacles
PAC526	x					
PAC526F	x	x				
PAC526FBP2	x	x				2
PAC526FBP4	x	x				4
PAC526FBP6	x	x				6
PAC526FW	x			x		
PAC526FWP2	x			x		2
PAC526FWP4	x			x		4
PAC526FWP6	x			x		6
PAC526FC	x	x	x			
PAC526FCW	x			x	x	
PAC526F-KIT		x				
PAC526FW-KIT				x		
PAC526CVR-KIT			x			
PAC526CVRW-KIT					x	



INSTALLER INSPIRED | milestone.com

USA P 866.977.3901 E chief@chiefmfg.com

CANADA P 877.345.4329 E canadainfo@milestone.com

EMEA P +31 495 580 840 E emea.sales@milestone.com

APAC P +852 2145 4099 E asia.chief@milestone.com

In British Columbia, Milestone AV Technologies ULC carries on business as MAVT Milestone AV Technologies ULC.
 ©2017 Milestone AV Technologies. 170046A 2/17 Chief is a registered trademark of Milestone AV Technologies. All other brand names or marks are used for identification purposes and are trademarks of their respective owners. All patents are protected under existing designations. Other patents pending.

milestone

BRANDS OF MILESTONE AV TECHNOLOGIES

Chief | Da-Lite | Sanus | Vaddio | Projecta