

NON-METALLIC • NON-CONDUCTIVE



Installed Gaskets
& NM Cable
Connectors

For Help
in Obtaining
**ENERGY
STAR**
rating



Prevents Air Infiltration in New Construction

Vapor Boxes
for Fans, Fixtures, Devices

A
Arlington

Single Drywall

SCREW-ON Vapor Boxes for Fixtures, Devices

NEW!

Arlington's non-metallic ONE-BOX™ fan, fixture and device boxes feature built-in flanges with gaskets attached that form a protective barrier against air infiltration, enabling installers to meet local codes where required.

Fast, easy, secure installation in new construction, our vapor boxes mount to wood or steel joists with nails or screws that ship captive.

ONE-BOX Vapor Boxes for Fixtures, Fans and Devices...

- Non-metallic, non-conductive
- For fixtures (round), fan or fixture (bar hanger) and devices (single and multiple gangs)
- No loose parts – ships with mounting screws or captive nails (on facing page) and installed NM cable connectors with gaskets attached
- For new construction with single or double drywall
- UL/CSA Listed

Patented. Other patents pending


for Fixtures

Installation cutaway




All Available with Ground Clip for Canada

NM Cable Connectors with Gasket material already **INSTALLED**

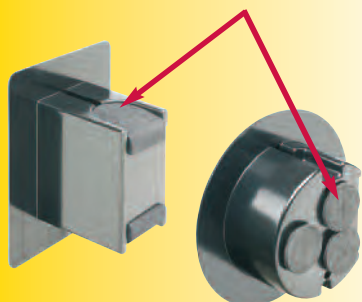

for Devices

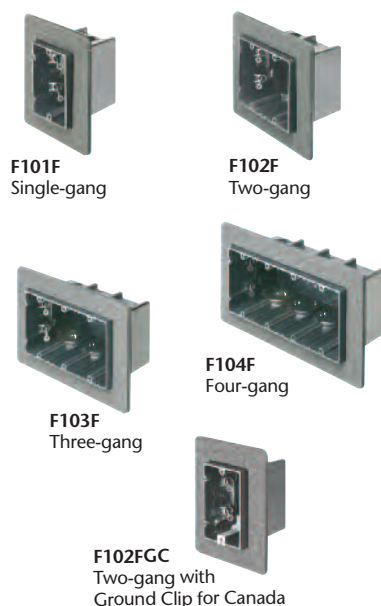

Screw-on Single Drywall

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
F426F	06903	Round for fixtures	28.0	20
F101F	12520	Single-gang for devices	22.0	25
F102F	06900	Two-gang for devices	42.0	10
F103F	06901	Three-gang for devices	59.0	10
F104F	06902	Four-gang for devices	81.0	10

Screw-on with Ground Clip for use in Canada (GC suffix)

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
F426FGC	06909	Round for fixtures	28.0	20
F101FGC	06905	Single-gang for devices	22.0	25
F102FGC	06906	Two-gang for devices	42.0	10
F103FGC	06907	Three-gang for devices	59.0	10
F104FGC	06908	Four-gang for devices	81.0	10

Includes Robertson head screws



NAIL-ON Vapor Boxes for Fixtures, Devices

for Fixtures



Gasket material attached to ALL flanges and knockouts

for Devices




FN101F
Single-gang

FN102F
Two-gang




FN103F
Three-gang

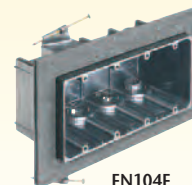

FN104F
Four-gang

FN430F ships ready to install a **FIXTURE** on ceilings with **Single Drywall**

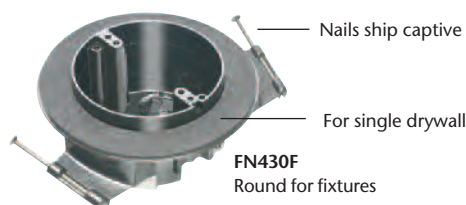

FN430F
Round for fixtures



FN430F
Round for fixtures
(back shown)



Nail-on Single Drywall

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
FN430F	15100	Round for fixtures	30.5	20
FN101F	15130	Single-gang for devices	23.0	20
FN102F	15132	Two-gang for devices	43.5	10
FN103F	15134	Three-gang for devices	63.5	10
FN104F	15136	Four-gang for devices	85.3	10

Voltage Separator

Divides power/low voltage in box



F102D
Voltage separator

Catalog Number	UPC/DEI/NAED Mfg. #018997	Low Voltage Separator	Unit/Std Pkg
F102D	43544	Divides power/low voltage in box	25
Fits these boxes installed w/ single drywall: Two, three, four-gang screw-on F102F, F103F, F104F (and GC styles)			
Two, three, four-gang nail-on FN102F, FN103F, FN104F (and GC styles) installed with single drywall (only)			

Nail-on with Ground Clip for use in Canada (GC suffix)

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
FN430FGC	15101	Round for fixtures	30.5	20
FN101FGC	15138	Single-gang for devices	23.0	20
FN102FGC	15140	Two-gang for devices	43.5	10
FN103FGC	15142	Three-gang for devices	63.5	10
FN104FGC	15144	Four-gang for devices	85.3	10

Includes Robertson head screws



FN102FGC
Two-gang with
Ground Clip for Canada

Ground Clip for use in Canada



Double Drywall

NAIL-ON Vapor Boxes for Fixtures, Devices


EXISTING CONSTRUCTION

for Fixtures




Nail-on
FN440F
for double drywall

for Devices

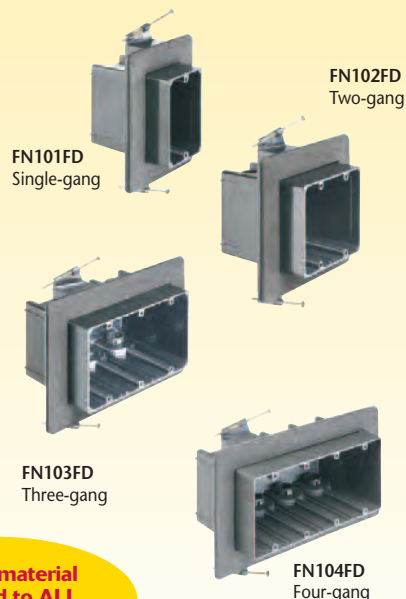

Gasket material
attached to ALL
flanges and knockouts

FN440F for installing FIXTURES on
Double Drywall ceilings

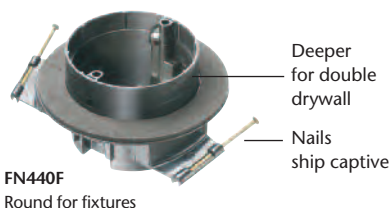

FN440F
Round for fixtures

Nail-on Double Drywall

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
FN440F	15120	Round for fixtures	39.5	20
FN101FD	15131	Single-gang for devices	28.0	20
FN102FD	15133	Two-gang for devices	53.0	10
FN103FD	15135	Three-gang for devices	77.8	10
FN104FD	15137	Four-gang for devices	103.5	10

For added convenience,
these nail-on boxes ship
with the nails captive

Nail-on with Ground Clip for use in Canada (GC suffix)

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
FN440FGC	15121	Round for fixtures	39.5	20
FN101FDGC	15139	Single-gang for devices	28.0	20
FN102FDGC	15141	Two-gang for devices	53.0	10
FN103FDGC	15143	Three-gang for devices	77.8	10
FN104FDGC	15145	Four-gang for devices	103.5	10

Includes Robertson head grounding screws



Made in USA




Arlington

Side Mount

Side Mount • SCREW-ON Vapor Boxes for Fans/Fixtures

for Fans or Fixtures

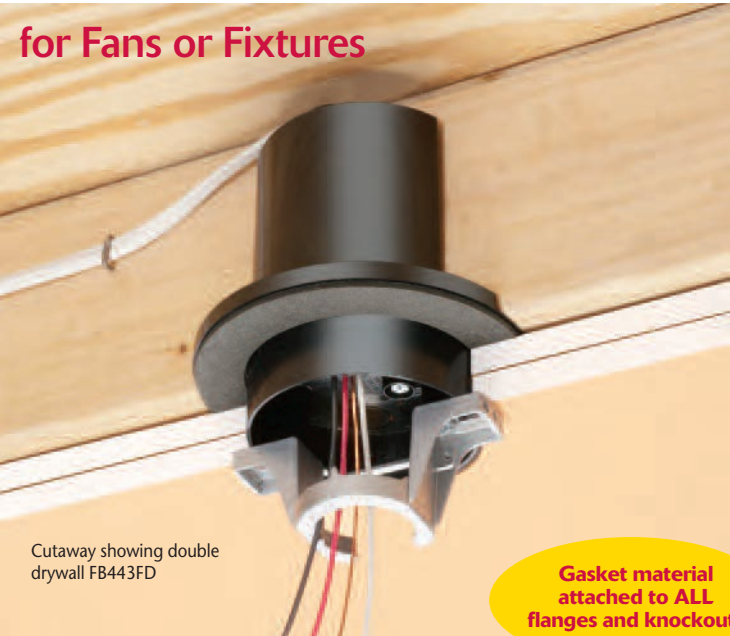

Cutaway showing double drywall FB443FD

Gasket material attached to ALL flanges and knockouts

Our economical L-shaped fan/fixture boxes mount securely to joist with a shipped-in-place center screw.

- Styles for single or double drywall
- Vapor barrier in box prevents air infiltration through ceiling or building envelope
- NM Cable Connectors and flange with Gasket material already INSTALLED
- Fan/fixture bracket installation screws ship captive
- UL Ratings: 70 lb fan/200 lb fixture
CSA: 50 lb fan or fixture



FB442FD shown with mud cover as shipped



Patented. Other patents pending



Single Drywall
FB443F



FB442FD



FB442F



FB443FD

Press on Fan/Fixture Box

Versatile, non-conductive box for new construction



FB426F



FB426F
(back shown)

Features and Benefits

- Flange with gasket attached forms a protective barrier against air infiltration
- NM Cable Connectors and flange with Gasket material already INSTALLED
- Includes captive installation screws for fan/fixture bracket
- Gripping tangs press-hold to the joist while you reach for your screwdriver
- UL rated: 70 lb. fan, 200 lb. fixture;
CSA rated: 50 lb. fan/fixture

Catalog Number	UPC/DEI/NAED Mfg. #018997	Description /Style	Unit/Std Pkg
FB426F	12521	For 1/2" or 5/8" Drywall 16.0 Cu. In.	25

Patented. Other patents pending

Screw-on Side Mount Single Drywall

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
FB442F	76220	Joist Mount	15.5	25
FB443F	76222	Fan or Fixture	18.8	25

Screw-on Side Mount Double Drywall

Catalog Number	UPC/DEI/NAED Mfg. #018997	Vapor Box Size/Use	Cubic Inches	Unit/Std Pkg
FB442FD	76221	Joist Mount	25.0	25
FB443FD	76223	Fan or Fixture	28.5	25

Add suffix "GC" to catalog number when ordering for use in Canada, i.e. FB442FGC, FB442FDGC.

Made in USA



Arlington

For New Construction Plastic Vapor Box with Adjustable Steel Bracket for Fans/Fixtures

Arlington's heavy-duty, non-metallic fan/fixture boxes feature

fully adjustable plated steel brackets that fit joists spaced 16" to 24" o.c.



Just like our vapor boxes for fixtures and devices, these fan/fixture boxes have built-in flanges with gaskets installed that form a protective barrier against air infiltration, so installers can meet residential codes where required.

Best of all, they deliver flush ceiling installations!

Fast, secure installation in new construction, our fan/fixture vapor boxes mount to wood joists with supplied screws.

FBR415F ships ready to install on SINGLE drywall;
FBR425F is for DOUBLE drywall.



FBR415F



FBR425F

- Non-metallic, non-conductive box, with fully adjustable steel bracket
- Position box anywhere along bracket
- Captive fan/fixture bracket installation screws, mud cover, installed NM cable connector, and all gasket material
- UL/CSA Listed



Arlington

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com
©2011 Arlington Industries, Inc.
REV1213/25M



Installation cutaway (single drywall shown)




FBR415F, FBR425F...for New Construction



1 Nail 'tooth' to joist to hold bracket in place temporarily.



2 Use supplied screws to secure bracket to joists.

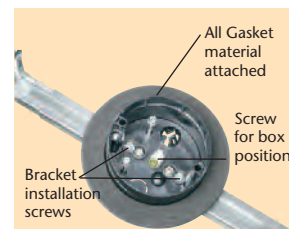

Inside FBR415F box



3 Loosen box screw (provided). Slide box along bracket to position box between joists.



4 Tighten box screw to lock box in position.



5 Remove captive installation screws to install fan/fixture mounting bracket (drywall installation not shown).

Catalog Number	UPC/DEI/NAED Mfg. #018997	Fan/Fixture Vapor Box Plastic box, adjustable steel bracket	Cubic Inches	Unit/Std Pkg
FBR415F	72204	for single drywall ceilings	18.3	5
FBR425F	72205	for double drywall ceilings	27.3	5

UL Fan Rated
70# at 24" o.c.
110# at 16" o.c.
UL Fixture Rated
90# at 24" o.c.
150# at 16" o.c.
Canadian Std. Rated
50# Fan/Fixture 16"-24" o.c.

Distributed by

NM Cable Connectors with Gasket material already INSTALLED



Non-metallic Vapor Boxes for Fans, Fixtures, Devices