

WG1

NEMA Rated Wire Gland Inlets

Description

Altronix WG1 facilitates wiring for all Altronix outdoor enclosures.



WG1

Specifications

Material

- Polyamide PA 6.
- Seal: Chloroprene-rubber (CR).
- phosphor-free;
- silicone-free;
- cadmium-free

Features

- Protection class: IP 68 - 5 bar / IP 69K.
- Optimum strain relief through clamping plates.
- Easy to assemble.
- Large clamping areas.

Physical and Environmental

Dimensions:

- Thread size: M16
- Thread length 10mm
- Spanner size 22mm

Product Weight 0.05 lb. (0.02 kg).

Shipping Weight 0.15 lb. (0.07 kg).


Temperature

Operating -20°C to 100°C (-4°F to 212°F).


Relative Humidity 85% +/-5%.

Dimensions and Drawing

Cable Gland

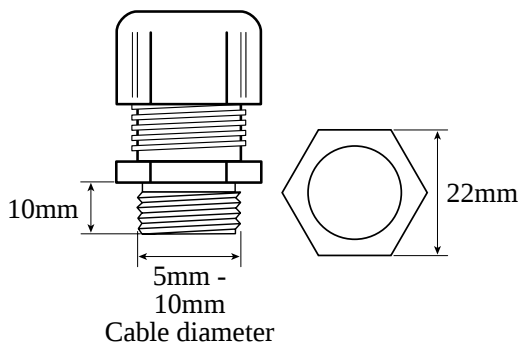

Counternut with collar

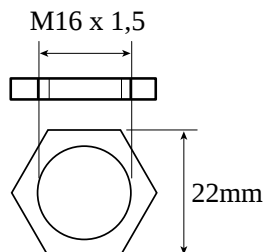

O - Ring

