

V50™

Colour selectable fire-rated LED downlight

- Two colour selectable from below the ceiling, 3000K & 4000K
- Ultra-low profile suitable for shallow 50mm ceiling voids
- Fully fire-rated for 30, 60 and 90 minute ceilings
- Strong, protected spring clips
- Fast, push-fit termination with remote driver
- Triac dimmable as standard (recommended dimmer list on JCC website)
- Twist & lock bezel design
- Available as complete fixture (JC1001) or without bezel (JC1001/NB)
- JC1001/NB requires separate bezel (JC1006)
- **NEW** 5 year warranty

✓ JC1001/CH



✓ JC1001/WH



✓ JC1001/BN



✓ JC1006/BR



✓ JC1006/BLK



NEW New product for 2018

5 year ext. warranty*

Dimmable as standard

60° beam angle

See p.18 and p.19 for accessories

Classification

Class 2
IP65 (standard) | 240V
IP20 (tilt) | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)

Finishes

Black (**BLK**), Brushed Brass (**BR**),
Brushed Nickel (**BN**),
Chrome (**CH**), White (**WH**)

Construction

Body: Steel
Lens: Polycarbonate
Bezel: Aluminium


Accessories

Converter plate (see p.18)
Concealer ring (see p.19)

Installation

Cut out Ø: 70mm

JC1001

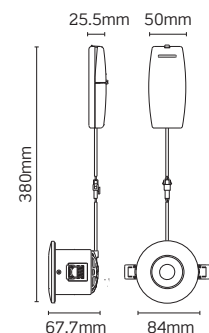

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC1001/NB	V50 Without bezel	3000K & 4000K	Yes	7.5W	600/650	80
JC1001	V50 With bezel (add suffix)	3000K & 4000K	Yes	7.5W	600/650	80
JC1001/WHEM	V50 emergency with bezel	3000K & 4000K	Yes	7.5W	600/650	80
JC1001/CHEM	V50 emergency with bezel	3000K & 4000K	Yes	7.5W	600/650	80
JC1001/BNEM	V50 emergency with bezel	3000K & 4000K	Yes	7.5W	600/650	80
JC1006	Separate bezel for V50 (add suffix) -	-	-	-	-	-

For Black add /**BLK** suffix, for Brushed Brass add /**BR** suffix, for Brushed Nickel add /**BN** suffix, for Chrome add /**CH** suffix, for White add /**WH** suffix.

*Requires online registration.