



2 year product guarantee

Fireguard LED

Interchangeable retrofit LED module

- Complies with 2014 Building regulations: Part B, C and E
- Interchangeable LED module with integral bezel
- Fully fire-rated for 30, 60 and 90 minute ceilings
- 30,000 hour life
- Triac dimmable as standard (trailing edge only**)

Classification

Class 2
IP20 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)

Finishes

Brushed Nickel (**BN**),
Chrome (**CH**), White (**WH**)

 

Construction

Body: Steel
Lens: Polycarbonate
Bezel: Aluminium

Installation

Cut out Ø: 74mm

JC94113LED

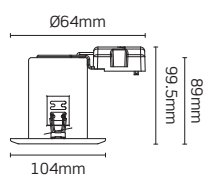

All data sheets and installation sheets available at jcc.co.uk

✓ JC94113LED3KWH



✓ JC94113LED3KBN



✓ JC94113LED3KCH



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC94113LED3K	Fireguard LED 38° beam angle	3000K	No	7.2W	450lm	63
JC94113LED4K	Fireguard LED 38° beam angle	4000K	No	7.2W	500lm	63

For Brushed Nickel add **BN** suffix, for Chrome add **CH** suffix, for White add **WH** suffix.

*Requires online registration.

**View recommended list on JCC website