

Twist & Lock

Fire-rated twist and lock mains downlight

- Twist & Lock lamp retainer for easy lamp removal
- Fire-rated 240V 50W MAX downlights, maintaining the fire-rating of ceilings
- Press-fit terminal, loop-in/loop-out
- Lamp not supplied

✓ JC94113WH



✓ JC94114CH



2 year
product guarantee

Classification

□ Class 2
IP20 | 240V

Lamp

GU10 (not supplied)

Finishes

Brushed Nickel (**BN**),
Chrome (**CH**), White (**WH**)


Construction

Body: Steel
Bezel: Aluminium


Installation

Cut out Ø:
JC94113 - 74mm
JC94114 - 85mm

JC94113

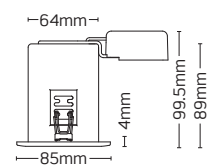

JC94114

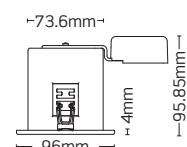

Code	Description	Lamp
JC94113	Fire-rated Twist & Lock	GU10 50W Max
JC94114	Fire-rated 15° tiltable Twist & Lock	GU10 50W Max

For Brushed Nickel add **BN** suffix, for Chrome add **CH** suffix, for White add **WH** suffix.