




Nebula™


Slim bezel LED downlight

- Up to 90 Lumens per circuit Watt
- IP44 protection against dust and moisture
- IP65 sealable gasket available on 8W, 12W and 15W variants
- Ideal for shallow ceiling voids
- Triac dimmable options available

 5 year ext. warranty*

 Dimmable options available

 40° (8W), 60° (12/15W) beam angle

 Emergency options available



Classification

- Class 2
- Class 1 (EM versions)
- IP44 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)

Finishes

White

Construction

Body: Aluminium
Lens: Glass
Bezel: Steel


Accessories

IP65 gasket for 8W 5pcs (JC95131)
IP65 gasket for 12W and 15W 5pcs (JC95130)


Installation

Cut out Ø: 8W - 64mm
12W/15W - 91mm

JC95101 / JC95102

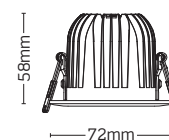

JC95111 / JC95112 / JC95121 / JC95122

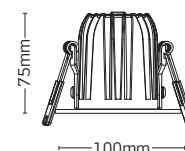

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC95101	Nebula LED Downlight 40° beam	3000K	No	8W	600	75
JC95101DIM	Nebula LED Downlight 40° beam	3000K	Yes	8W	600	75
JC95102	Nebula LED Downlight 40° beam	4000K	No	8W	650	81
JC95102DIM	Nebula LED Downlight 40° beam	4000K	Yes	8W	650	81
JC95111	Nebula LED Downlight 60° beam	3000K	No	12W	900	75
JC95111DIM	Nebula LED Downlight 60° beam	3000K	Yes	12W	900	75
JC95112	Nebula LED Downlight 60° beam	4000K	No	12W	1000	83
JC95112DIM	Nebula LED Downlight 60° beam	4000K	Yes	12W	1000	83
JC95121	Nebula LED Downlight 60° beam	3000K	No	15W	1200	80
JC95121DIM	Nebula LED Downlight 60° beam	3000K	Yes	15W	1200	80
JC95122	Nebula LED Downlight 60° beam	4000K	No	15W	1350	90
JC95122DIM	Nebula LED Downlight 60° beam	4000K	Yes	15W	1350	90
JC95130	IP65 gasket 5pcs	-	-	12W/15W	-	-
JC95131	IP65 gasket 5pcs	-	-	8W	-	-

For emergency versions add **EM** suffix

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk