



5 year  
ext. warranty\*



Dimmable  
options available



40°  
beam angle



Emergency  
options available

# Nebula™ Darklight

## Slim bezel tiltable LED downlight

- Recessed LED module for low glare applications
- 35° tiltable
- Slim profile bezel for discrete installations
- Triac dimmable options available



### Classification

- Class 2
- ⊕ Class 1 (EM versions)
- IP20 | 240V

### LED

3000K | CRI: Ra (80)  
4000K | CRI: Ra (80)

### Finishes

White


### Construction

Body: Aluminium  
Lens: Glass  
Bezel: Steel


### Installation

Cut out Ø: 8W - 75mm  
12W/15W - 95mm

JC95201 / JC95202

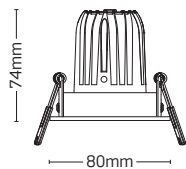

JC95211 / JC95212  
/ JC95221 / JC95222

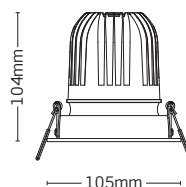

All data sheets and installation sheets  
available at [jcc.co.uk](http://jcc.co.uk)

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC95201	Nebula Darklight 40° beam	3000K	No	8W	525	66
JC95201DIM	Nebula Darklight 40° beam	3000K	Yes	8W	525	66
JC95202	Nebula Darklight 40° beam	4000K	No	8W	575	72
JC95202DIM	Nebula Darklight 40° beam	4000K	Yes	8W	575	72
JC95211	Nebula Darklight 40° beam	3000K	No	12W	800	67
JC95211DIM	Nebula Darklight 40° beam	3000K	Yes	12W	800	67
JC95212	Nebula Darklight 40° beam	4000K	No	12W	850	71
JC95212DIM	Nebula Darklight 40° beam	4000K	Yes	12W	850	71
JC95221	Nebula Darklight 40° beam	3000K	No	15W	1050	70
JC95221DIM	Nebula Darklight 40° beam	3000K	Yes	15W	1050	70
JC95222	Nebula Darklight 40° beam	4000K	No	15W	1100	73
JC95222DIM	Nebula Darklight 40° beam	4000K	Yes	15W	1100	73

For emergency versions add **EM** suffix

\*Requires online registration.