

Nebula™ High Output

Low profile LED downlight

- Slim profile bezel for discrete installations
- Highly efficient, up to 97 Lumens per circuit Watt
- Ideal for shallow ceiling voids
- Triac dimmable as standard

✓ JC95301



✓ JC95305



NEW

New product
for 2018



5 year
ext. warranty*



Dimmable
as standard



36° (8W), 60° (10W/13W)
beam angle

Classification

Class 2
IP65 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)

Finishes

White


Construction

Body: Aluminium
Lens: Polycarbonate
Bezel: Aluminium


Installation

Cut out Ø: 8W - 68-75mm
10W/13W - 90-95mm

JC95301 / JC95302

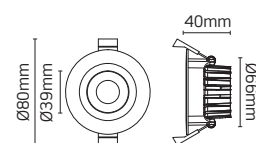

JC95303 / JC95304 JC95305 / JC95306

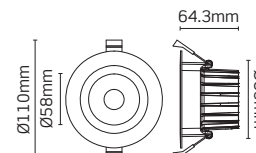

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC95301	Slim Bezel LED Downlight 36° beam	3000K	Yes	8W	770	97
JC95302	Slim Bezel LED Downlight 36° beam	4000K	Yes	8W	840	105
JC95303	Slim Bezel LED Downlight 60° beam	3000K	Yes	10W	820	82
JC95304	Slim Bezel LED Downlight 60° beam	4000K	Yes	10W	890	89
JC95305	Slim Bezel LED Downlight 60° beam	3000K	Yes	13W	950	73
JC95306	Slim Bezel LED Downlight 60° beam	4000K	Yes	13W	1200	92

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk