

Coral LED™ 16W

High performance commercial LED downlight

- 2x18W CFL direct replacement
- Structural heat sink removes the need for noisy and inefficient cooling fans
- CRI 90, ideal for retail applications



5 year
ext. warranty*



Dimmable
options available



Emergency
options available



See p.41
for rim options

Classification

⊕ Class 1**

□ Class 2

IP20 (IP65 rim optional) | 240V

LED

4000K | CRI: Ra (90)

Finishes

See rim options on p.41

Construction

Body: Aluminium

Lens: Polycarbonate

Accessories

Rim options (see p.41):

JC5052 N / JC5054 / JC5060
/ JC5368 / JC5110 / JC5118

Installation

Cut out Ø: 212mm


JC5410



~260mm~
~212mm~

Dimmable

Standard

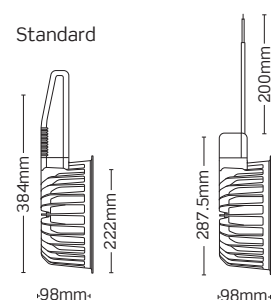

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC5421**	Coral LED	4000K	No	16W	1600	100
JC5421DALI	Coral LED DALI	4000K	Yes	16W	1600	100
JC5421DSI	Coral LED DSI	4000K	Yes	16W	1600	100
JC5421/1-10V	Coral LED 1-10V	4000K	Yes	16W	1600	100
JC5421EM**	Coral LED emergency	4000K	No	16W	1600	100
JC5421EMDALI**	Coral LED DALI emergency	4000K	Yes	16W	1600	100
JC5421EMDSI**	Coral LED DSI emergency	4000K	Yes	16W	1600	100
JC5421EM/1-10V**	Coral LED 1-10V emergency	4000K	Yes	16W	1600	100
JC5410	Coral LED Concealer ring	-	-	-	-	-

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk