




Coral LED™ 32W


High output commercial LED downlight

- 2x32W CFL direct replacement
- Structural heat sink removes the need for noisy and inefficient cooling fans
- CRI 90, ideal for retail applications

 5 year ext. warranty*

 Dimmable options available


 Emergency options available

 See p.41 for rim options



Classification

 Class 1**

 Class 2

IP20 (IP65 rim optional) | 240V

LED

4000K | CRI: Ra (90)

Finishes

See rim options on p.41

Construction

Body: Aluminium

Lens: Polycarbonate

Accessories

Rim options (see p.41):

JC5052 N / JC5054 / JC5060

/ JC5368 / JC5110 / JC5118

Installation

Cut out Ø: 212mm


JC5410



-260mm-
-212mm-

Dimmable

Standard

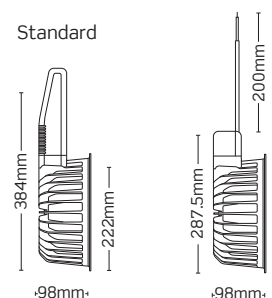

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC5422**	Coral LED	4000K	No	32W	2800	88
JC5422DALI	Coral LED DALI	4000K	Yes	32W	2800	88
JC5422DSI	Coral LED DSI	4000K	Yes	32W	2800	88
JC5422/1-10V	Coral LED 1-10V	4000K	Yes	32W	2800	88
JC5422EM**	Coral LED emergency	4000K	No	32W	2800	88
JC5422EMDALI**	Coral LED DALI emergency	4000K	Yes	32W	2800	88
JC5422EMDSI**	Coral LED DSI emergency	4000K	Yes	32W	2800	88
JC5422EM/1-10V**	Coral LED 1-10V emergency	4000K	Yes	32W	2800	88
JC5410	Coral LED Concealer ring	-	-	-	-	-

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk