



New product
for 2018



5 year
ext. warranty*



20°/45°/60°
beam angle options



Produced to order
call 01243 838999



JC84312BLK

Classification

Class 1
IP54 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)


Finishes

Black (**BLK**), White (**WH**)

Construction

Body: Aluminium
Lens: Glass

Surface Downlight 35W

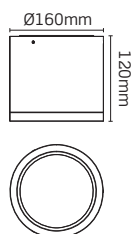

All data sheets and installation sheets
available at jcc.co.uk

Surface High Output 35W

High output cylindrical surface mounted LED downlight

- Stylish design ideal for contemporary commercial applications
- Quick and simple surface mount installation
- Ultra efficient, up to 120 Lumens per circuit Watt
- 24°, 45° and 60° beam angle options available
- Produced to order, contact JCC customer services on **01243 838999**



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC84312	Surface Downlight 24° beam	3000K	No	35W	3850	110
JC84315	Surface Downlight 24° beam	4000K	No	35W	4200	120
JC84313	Surface Downlight 45° beam	3000K	No	35W	3850	110
JC84316	Surface Downlight 45° beam	4000K	No	35W	4200	120
JC84314	Surface Downlight 60° beam	3000K	No	35W	3850	110
JC84317	Surface Downlight 60° beam	4000K	No	35W	4200	120

For Black add **BLK** suffix, for White add **WH** suffix.

Produced to order, contact JCC customer services on **01243 838999**.

*Requires online registration.