



Skytile® 28W


High performance LED 28W flat panel

- Outperforms traditional 4x18W fluorescent
- 7 year extended warranty, including 2 year on-site support
- Up to 107 lumens per circuit Watt
- Available in three colour temperatures 3000K, 4000K and 4700K
- Suspension kit and surface mount box available

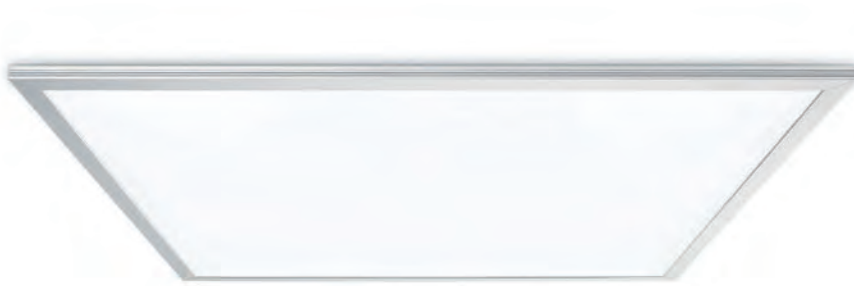

 7 year ext. warranty* (incl. 2 year on-site)

 Dimmable options available



 Sensing options available

 Emergency options available



White frame - JC71276WH

Classification

-  Class 2
 -  Class 1 (EM00172)
- IP44 | 240V

LED

3000K | CRI: Ra (80)
4000K | CRI: Ra (80)
4700K | CRI: Ra (80)

Finishes

Silver, White (WH)**

Construction

Body: Aluminium
Diffuser: Opal polycarbonate


Accessories

Surface mount box JC71262 (see p.72), 1.5m Suspension kit JC71311 (see p.73)

Installation

Cut out: 600mm x 600mm

JC71351

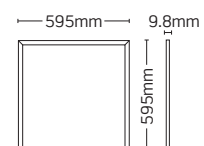

All data sheets and installation sheets available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71351	Skytile	3000K	No	28W	2700	96
JC71351DALI	Skytile DALI	3000K	Yes	28W	2700	96
JC71351DSI	Skytile DSI	3000K	Yes	28W	2700	96
JC71351/1-10V	Skytile 1-10V	3000K	Yes	28W	2700	96
JC71355	Skytile	4000K	No	28W	3000	107
JC71355DALI	Skytile DALI	4000K	Yes	28W	3000	107
JC71355DSI	Skytile DSI	4000K	Yes	28W	3000	107
JC71355/1-10V	Skytile 1-10V	4000K	Yes	28W	3000	107
JC71276	Skytile	4700K	No	28W	3000	107
JC71276DALI	Skytile DALI	4700K	Yes	28W	3000	107
JC71276DSI	Skytile DSI	4700K	Yes	28W	3000	107
JC71276/1-10V	Skytile 1-10V	4700K	Yes	28W	3000	107
EM00172	Plug and Play Emergency Pack	-	-	-	-	-
SPR0579	Armstrong oracle T-Clip Bracket	-	-	-	-	-
JC71311	4 wire suspension kit (1.5m)	-	-	-	-	-
JC71262	600 x 600mm Surface mount box	-	-	-	-	-

**For White add WH suffix (available for 4700K options only).