


Skytile® 36W

High performance LED 36W flat panel

-  7 year ext. warranty* (incl. 2 year on-site)
-  Dimmable options available
-  Emergency options available

- Ideal for higher ceilings over 2.8m
- 7 year extended warranty, including 2 year on-site support
- Up to 106 lumens per circuit Watt
- Available in three colour temperatures 3000K, 4000K and 4700K
- Suspension kit and surface mount box available

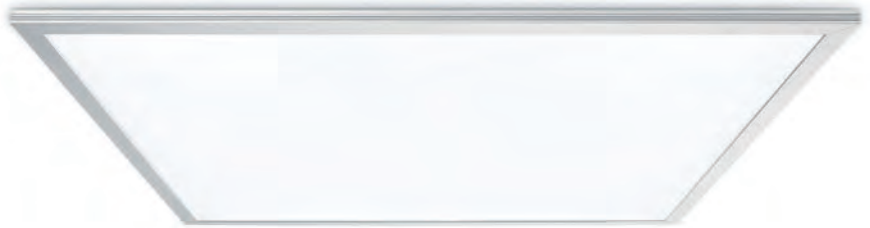

Classification

- Class 2
 - Class 1 (EM00172)
- IP44 | 240V

LED

- 3000K | CRI: Ra (80)
- 4000K | CRI: Ra (80)
- 4700K | CRI: Ra (80)

Finishes

Silver

Construction

Body: Aluminium
Diffuser: Opal polycarbonate


Accessories

Surface mount box **JC71262**
(see p.72), 1.5m Suspension kit
JC71311 (see p.73)

Installation

Cut out: 600mm x 600mm

JC71353

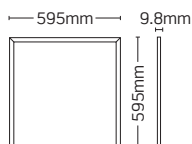

All data sheets and installation sheets available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71353	Skytile	3000K	No	36W	3500	97
JC71353DALI	Skytile DALI	3000K	Yes	36W	3500	97
JC71353DSI	Skytile DSI	3000K	Yes	36W	3500	97
JC71353/1-10V	Skytile 1-10V	3000K	Yes	36W	3500	97
JC71357	Skytile	4000K	No	36W	3800	106
JC71357DALI	Skytile DALI	4000K	Yes	36W	3800	106
JC71357DSI	Skytile DSI	4000K	Yes	36W	3800	106
JC71357/1-10V	Skytile 1-10V	4000K	Yes	36W	3800	106
JC71277	Skytile	4700K	No	36W	3800	106
JC71277DALI	Skytile DALI	4700K	Yes	36W	3800	106
JC71277DSI	Skytile DSI	4700K	Yes	36W	3800	106
JC71277/1-10V	Skytile 1-10V	4700K	Yes	36W	3800	106
EM00172	Plug and Play Emergency Pack	-	-	-	-	-
SPR0579	Armstrong oracle T-Clip Bracket	-	-	-	-	-
JC71311	4 wire suspension kit (1.5m)	-	-	-	-	-
JC71262	600 x 600mm Surface mount box	-	-	-	-	-

*Requires online registration.