


Skytile® Base

Direct fluorescent replacement

- 32W LED flat panel
- 88 lumens per circuit Watt
- 4200K colour temperature
- IP20 protection

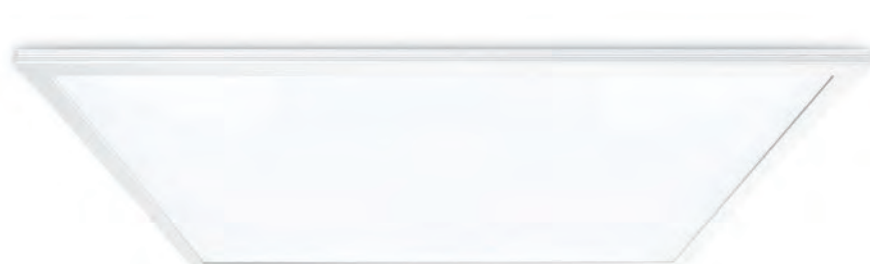

3 year
ext. warranty*



Emergency
options available

Classification

□ Class 2
⊕ Class 1 (EM00172)
IP20 | 240V

LED

4200K | CRI: Ra (80)

Finishes

White

Construction

Body: Aluminium
Diffuser: Opal polycarbonate


Accessories

Surface mount box JC71262
(see p.72), 1.5m Suspension kit
JC71311 (see p.73)

Installation

Cut out: 600mm x 600mm

JC71676

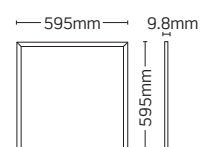

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71676	Skytile Base	4200K	No	32W	2800	88
SPR0579	Armstrong oracle T-Clip Bracket	-	-	-	-	-
EM00172	Plug and Play Emergency Pack	-	-	-	-	-
JC71311	4 wire suspension kit (1.5m)	-	-	-	-	-
JC71262	600 x 600mm Surface mount box	-	-	-	-	-

*Requires online registration.