

Skytile® Linear 1200 x 300

High performance linear LED flat panels

- High performance LED 36W recessed LED flat panel
- Quick and easy installation
- 7 year extended warranty, including 2 year on-site support
- 100 lumens per circuit Watt




7 year ext. warranty*
(incl. 2 year on-site)



Dimmable
options available



Emergency
options available

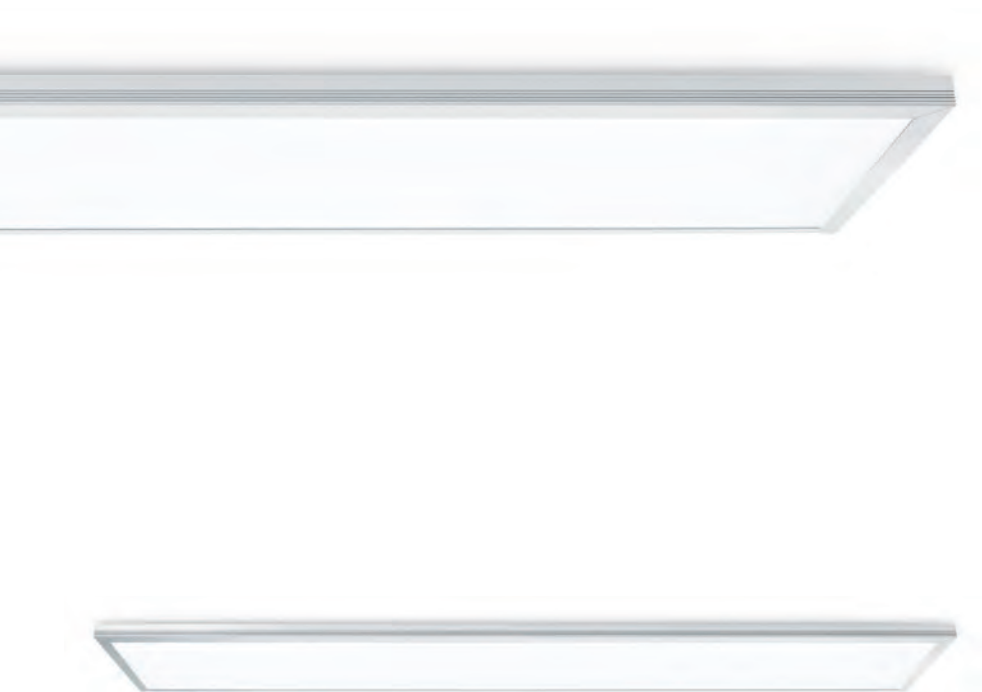

Classification

Class 2

Class 1 (EM00172)

IP44 | 240V

LED

4700K | CRI: Ra (80)

Finishes

Silver

Construction

Body: Aluminium

Diffuser: Opal polycarbonate


Accessories

Surface mount box **JC71299**
(see p.72), 1.5m Suspension kit
JC71311 (see p.73)

Installation

Cut out: 1200mmx300mm

JC71359

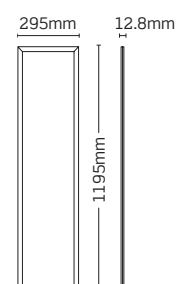

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71359	Skytile Linear	4700K	No	36W	3600	100
JC71359/DALI	Skytile Linear DALI	4700K	Yes	36W	3600	100
JC71359/DSI	Skytile Linear DSI	4700K	Yes	36W	3600	100
JC71359/1-10V	Skytile Linear 1-10V	4700K	Yes	36W	3600	100
EM00172	Plug and Play Emergency Pack	-	-	-	-	-
JC71311	4 wire suspension kit (1.5m)	-	-	-	-	-
JC71299	1200 x 300mm Surface mount box	-	-	-	-	-

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk