





NEW New product for 2018

 3 year ext. warranty*

 120° beam angle


 Sensing options available

 Emergency options available


ToughLED™ Weatherproof 5ft

Efficient, highly durable batten

- Ultra efficient, up to 126 lumens per circuit Watt
- Stainless steel anti-tamper clips
- Polycarbonate diffuser, ABS body, suitable for food preparation areas
- Press-fit terminals, loop in loop out for quick and simple installation
- Available with white opal or frosted diffuser

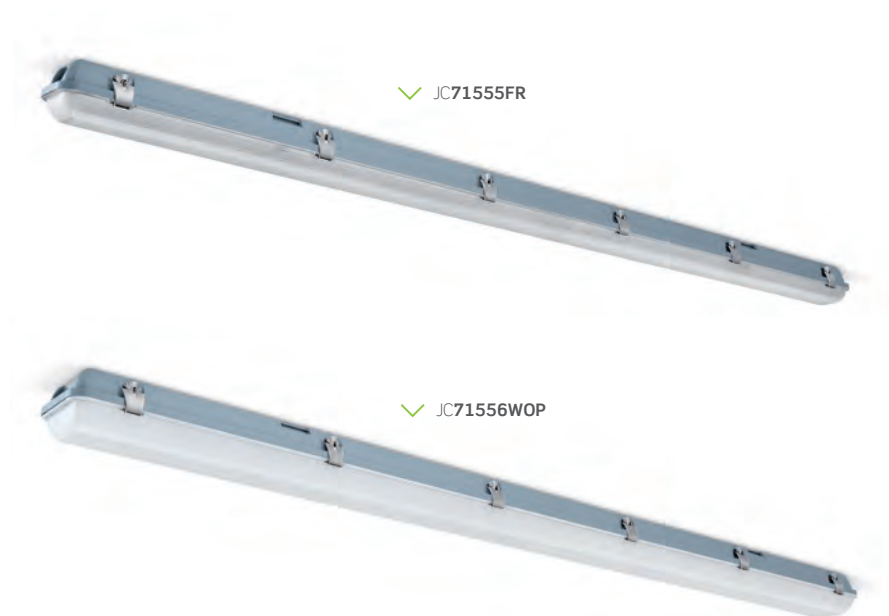

Classification

 Class 1
IP65 | 240V

LED

4000K | CRI: Ra (80)


Finishes

Grey

Construction

Body: ABS
Diffuser: Polycarbonate

JC71555 / JC71556

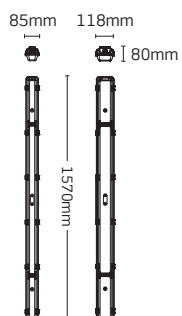

All data sheets and installation sheets available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens (FR)	Lumens (WOP)
JC71555	Weatherproof 5ft single	4000K	No	27W	3400	3200
JC71555MW	Weatherproof 5ft single m/w on/off	4000K	No	27W	3400	3200
JC71555EM	Weatherproof 5ft single emerg.	4000K	No	27W	3400	3200
JC71555MWEM	Weatherproof 5ft single m/w on/off em.	4000K	No	27W	3400	3200
JC71556	Weatherproof 5ft twin	4000K	No	57W	7000	6150
JC71556MW	Weatherproof 5ft twin m/w on/off	4000K	No	57W	7000	6150
JC71556EM	Weatherproof 5ft twin emerg.	4000K	No	57W	7000	6150
JC71556MWEM	Weatherproof 5ft twin m/w on/off em.	4000K	No	57W	7000	6150

For Frosted Diffuser add **FR** suffix, for White Opal Diffuser add **WOP** suffix.

*Requires online registration.