

OxfordLED™ 4ft

The 36W T8 fluorescent retrofit

- Hinged for simple installation
- Designed for surface mounting on solid ceilings
- 50% energy saving against 36W T8 fluorescent
- Smooth even light distribution, no visible hotspots



5 year
ext. warranty*



Emergency
options available



Classification

⊕ Class 1
IP20 | 240V

LED

4000K | CRI: Ra (80)


Finishes

White

Construction

Body: Steel
Diffuser: Polycarbonate

JC71411

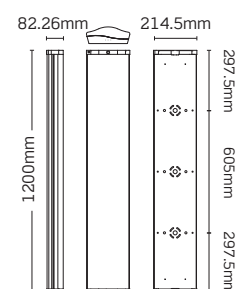

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71411	OxfordLED 4ft single	4000K	No	20W	2000	100
JC71411EM	OxfordLED 4ft single emergency	4000K	No	20W	2000	100
JC71412	OxfordLED 4ft twin	4000K	No	40W	4000	100
JC71412EM	OxfordLED 4ft twin emergency	4000K	No	40W	4000	100

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk