

OxfordLED™ 5ft

The 58W T8 fluorescent retrofit


 5 year ext. warranty*

 Emergency options available

- Hinged for simple installation
- Designed for surface mounting on solid ceilings
- 50% energy saving against 36W T8 fluorescent
- Smooth even light distribution, no visible hotspots



Classification

 Class 1
IP20 | 240V

LED

4000K | CRI: Ra (80)


Finishes

White

Construction

Body: Steel
Diffuser: Polycarbonate

JC71413

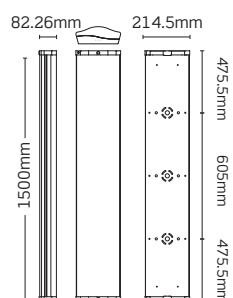

All data sheets and installation sheets available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71413	OxfordLED 5ft single	4000K	No	30W	3000	100
JC71413EM	OxfordLED 5ft single emergency	4000K	No	30W	3000	100
JC71414	OxfordLED 5ft twin	4000K	No	60W	6000	100
JC71414EM	OxfordLED 5ft twin emergency	4000K	No	60W	6000	100
JC71415	OxfordLED 5ft high output twin	4000K	No	80W	8000	100
JC71415EM	OxfordLED 5ft high output twin emergency	4000K	No	80W	8000	100

*Requires online registration.