


# Toughbay™ Circular 100W

Direct replacement for 150W HID metal halide

- 5 year extended warranty, including 2 year on-site support
- 105° beam angle without reflector
- Supplied with mounting ring and IP67 connector as standard
- 60° reflector beam angle option
- Suitable for high mounting industrial applications
- IP65 - Suitable for areas with high salt/moisture content
- 1-10V dimmable as standard




 5 year ext. warranty\*  
(inc. 2 year on site)

 Dimmable  
as standard

 Emergency  
options available

## Classification

 Class 1  
IP65 | 240V

## LED

5700K | CRI: Ra (80)

## Finishes

Black (**BLK**), White (**WH**)


## Construction

Body: Aluminium  
Lens: Polycarbonate


## Accessories

IP65 Connector, 60° beam reflector, Surface mount bracket (see p.113)

## JC71810BLK / JC71810WH

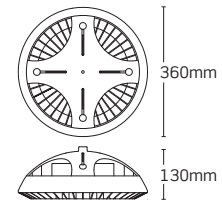

## JC71810BLKEM / JC71810WHEM

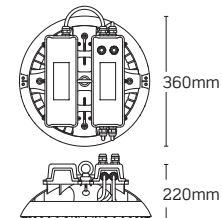

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71810BLK	Toughbay Circular black	5700K	Yes	100W	10,600	106
JC71810WH	Toughbay Circular white	5700K	Yes	100W	10,600	106
JC71810BLKEM	Toughbay Circular emergency black	5700K	Yes	100W	10,600	106
JC71810WHEM	Toughbay Circular emergency white	5700K	Yes	100W	10,600	106

\*Requires online registration.

All data sheets and installation sheets available at [jcc.co.uk](http://jcc.co.uk)