

# Toughbay™ Circular 180W

Direct replacement for 250W HID metal halide


 5 year ext. warranty\*  
(inc. 2 year on site)

 Dimmable  
as standard

 Emergency  
options available

- 5 year extended warranty, including 2 year on-site support
- 105° beam angle without reflector
- Supplied with mounting ring and IP67 connector as standard
- 60° reflector beam angle option
- Suitable for high mounting industrial applications
- IP65 - Suitable for areas with high salt/moisture content
- 1-10V dimmable as standard

## Classification

 Class 1  
IP65 | 240V

## LED

5700K | CRI: Ra (80)

## Finishes

Black


## Construction

Body: Aluminium  
Lens: Polycarbonate


## Accessories

IP65 Connector, 60° beam reflector, Surface mount bracket (see p.113)

## JC71811BLK

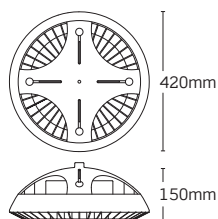

## JC71811BLKEM

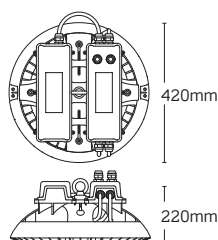

All data sheets and installation sheets available at [jcc.co.uk](http://jcc.co.uk)



Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC71811BLK	Toughbay Circular	5700K	Yes	180W	19,700	110
JC71811BLKEM	Toughbay Circular emergency	5700K	Yes	180W	19,700	110

\*Requires online registration.